

TYPE CSLT


Features

- Manufactured from high strength seamless copper tubing
- Electro-Tin plated
- Chamfered entry
- 2-hole tang provides maximum secureness, more contact surface and prevents rotation
- Color coded
- UL467 Listed for grounding and bonding applications, #8-#2 solid, 500kcmil - 8 AWG
- Suitable for use in circuits rated 35KV or less, proper high voltage spacing and insulation techniques must be used
- UL Listed and CSA Certified with ILSCO and major competitor's compression tools

Benefits

- Offers maximum conductivity and excellent crimping characteristics
- Provides low contact resistance
- For easy conductor insertion
- 2nd hole slotted to accommodate variable spacing requirements
- Identifies the proper compression die
- Application versatility
- Reduces inventory requirements

A

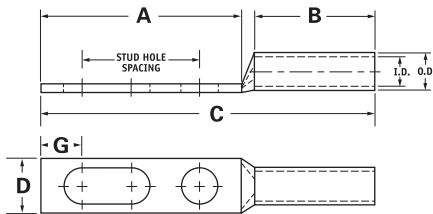

Catalog Number	Wire Size	Alt Wire Size	Expanded* Wire Range	Bolt Size	Mtg. Hole Dia.	Mtg. Hole Spacing	Dimensions					Die Color Code	Die Index	O.D.	I.D.
							A	B	C	D	G				
CLWDS-350-38-1-134	350kcmil	250 I,K,M FLEX 262.2 DLO	350kcmil - 3/0 AWG	1/2	0.406	1 to 1-3/4	2.625	2.000	5.248	1.291	0.414	RED	I-71	0.89	0.703
CLWDS-350-12-1-134	350kcmil	250 I,K,M FLEX 262.2 DLO	350kcmil - 3/0 AWG	1/2	0.562	1 to 1-3/4	3.000	2.000	5.623	1.291	0.546	RED	I-71	0.89	0.703
CLWDS-400-38-1-134	400kcmil	300 G,H,I,K,M FLEX 313.1 DLO	400kcmil - 4/0 AWG	3/8	0.406	1 to 1-3/4	2.625	2.125	5.417	1.365	0.414	BLUE	I-76	0.937	0.75
CLWDS-400-12-1-134	400kcmil	300 G,H,I,K,M FLEX 313.1 DLO	400 kcmil - 4/0 AWG	1/2	0.562	1 to 1-3/4	3.000	2.125	5.792	1.365	0.546	BLUE	I-76	0.937	0.75
CLWDS-500-12-1-134	500kcmil	350 G,H,I,K,M FLEX 373.7 DLO	500kcmil - 250kcmil	1/2	0.562	1 to 1-3/4	3.000	2.250	5.982	1.535	0.546	BROWN	I-87	1.064	0.828
CLWDS-600-12-1-134	600kcmil	400 G,H,I,K,M FLEX 444.4 DLO	600kcmil - 250kcmil	1/2	0.562	1 to 1-3/4	3.000	2.687	6.496	1.712	0.546	GREEN	I-94	1.187	0.92
CLWDS-650-12-1-134	650kcmil	500 G,H,I,K,M FLEX 535.3 DLO	650kcmil - 350kcmil	1/2	0.562	1 to 1-3/4	3.000	2.687	6.556	1.764	0.546	PINK	I-99	1.217	0.958
CLWDS-700-12-1-134	700kcmil	500 G,H,I & K,M FLEX 535.3 DLO	700kcmil - 350kcmil	1/2	0.991	1 to 1-3/4	3.000	2.687	6.556	1.816	0.546	PINK	I-99	1.25	0.991
CLWDS-750-12-1-134	750kcmil	600 G,H,I,M FLEX 646.4 DLO	750kcmil - 500kcmil	1/2	0.562	1 to 1-3/4	3.000	2.875	6.777	1.901	0.546	BLACK	I-106	1.313	1.031
CLWDS1000-12-1-134	1000kcmil	750 G,H,I FLEX 777.7 DLO	1000kcmil - 750kcmil	1/2	0.562	1 to 1-3/4	3.000	3.000	7.025	2.169	0.546	WHITE	I-125	1.5	1.172

All wire sizes, unless noted otherwise, are American Wire Gauge (AWG)

* When installed with specified dieless tools

UL File E6207