

TYPE ILSCONS

Features

- Manufactured from high strength copper alloy
- Electro-tin plated
- Packaged in convenient small quantities
- UL Listed and CSA Certified, 90° C

Benefits

- Provides maximum conductivity
- Provides low contact resistance
- Can be displayed on merchandise racks
- Ensures reliability for copper conductor

A1



Fig. 1

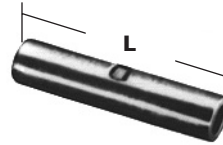


Fig. 2

Catalog Number	Figure Number	Wire Range	L
44600-B20	1	18-22	.33
44610-B20	1	14-16	.33
44620-B20	1	10-12	.33
44630-B10	1	8	.38
44640-B10	1	6	.46
44650-B10	1	4	.54
44800-B20	2	18-22	.63
44810-B20	2	14-16	.63
44820-B20	2	10-12	.82
44830-B10	2	8	.77
44840-B10	2	6	1.02
44850-B10	2	4	1.20

All wire sizes, unless noted otherwise, are American Wire Gauge (AWG)

Can be supplied in bulk. Consult factory for part number.

UL File E158587