

# ILSCO Non-Insulated Ring Terminals

RoHS  
Compliant

UL  
LISTED  
8M24



## TYPE ILSCONS


### Features

- Manufactured from high strength copper alloy
- Electro-tin plated
- Silver solder brazed seam
- Packaged in convenient small quantities
- UL Listed and CSA Certified, 90° C

### Benefits

- Provides maximum conductivity
- Provides low contact resistance
- May be crimped anywhere and will not split open, even under extreme operating stresses
- Can be displayed on merchandise racks
- Ensures reliability for copper conductor

A1

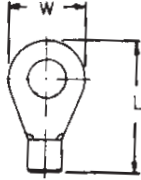

Catalog Number	Wire Range	Stud Size	Dimensions	
			L	W
44100-B20	18-22	4	.45	.20
44101-B20	18-22	6	.62	.25
44102-B20	18-22	8	.75	.31
44103-B20	18-22	10	.75	.31
44104-B20	18-22	1/4	.94	.47
44105-B20	18-22	5/16	.94	.47
44106-B20	18-22	3/8	.97	.53
44110-B20	14-16	4	.95	.25
44111-B20	14-16	6	.71	.31
44112-B20	14-16	8	.71	.31
44113-B20	14-16	10	.71	.31
44114-B20	14-16	1/4	.94	.46
44115-B20	14-16	5/16	.94	.46
44116-B20	14-16	3/8	.97	.53

All wire sizes, unless noted otherwise, are American Wire Gauge (AWG)  
Can be supplied in bulk. Consult factory for part number. UL File E158587

