

ILSCO Non-Insulated Ring Terminals

RoHS
Compliant

UL
LISTED
8M24




TYPE ILSCONS

Features

- Manufactured from high strength copper alloy
- Electro-tin plated
- Silver solder brazed seam
- Packaged in convenient small quantities
- UL Listed and CSA Certified, 90° C

Benefits

- Provides maximum conductivity
- Provides low contact resistance
- May be crimped anywhere and will not split open, even under extreme operating stresses
- Can be displayed on merchandise racks
- Ensures reliability for copper conductor

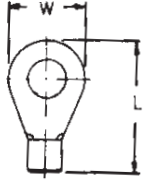

| Catalog Number | Wire Range | Stud Size | Dimensions | |
|----------------|------------|-----------|------------|-----|
| | | | L | W |
| 44120-B20 | 10-12 | 6 | .90 | .37 |
| 44121-B20 | 10-12 | 8 | .90 | .37 |
| 44122-B20 | 10-12 | 10 | .90 | .37 |
| 44123-B20 | 10-12 | 1/4 | 1.01 | .52 |
| 44124-B20 | 10-12 | 5/16 | 1.01 | .52 |
| 44125-B20 | 10-12 | 3/8 | 1.01 | .59 |
| 44126-B20 | 10-12 | 7/16 | 1.13 | .71 |
| 44127-B20 | 10-12 | 1/2 | 1.13 | .71 |
| 44130-B10 | 8 | 10 | 1.20 | .59 |
| 44131-B10 | 8 | 1/4 | 1.20 | .59 |
| 44140-B10 | 6 | 10 | 1.18 | .47 |
| 44141-B10 | 6 | 1/4 | 1.18 | .47 |
| 44142-B10 | 6 | 5/16 | 1.26 | .63 |
| 44143-B10 | 6 | 3/8 | 1.26 | .63 |

All wire sizes, unless noted otherwise, are American Wire Gauge (AWG)
Can be supplied in bulk. Consult factory for part number. UL File E158587