

ILSCO Non-Insulated Ring Terminals

RoHS
Compliant

UL
LISTED
8M24

CSA

TYPE ILSCONS


Features

- Manufactured from high strength copper alloy
- Electro-tin plated
- Silver solder brazed seam
- Packaged in convenient small quantities
- UL Listed and CSA Certified, 90° C

Benefits

- Provides maximum conductivity
- Provides low contact resistance
- May be crimped anywhere and will not split open, even under extreme operating stresses
- Can be displayed on merchandise racks
- Ensures reliability for copper conductor

A1

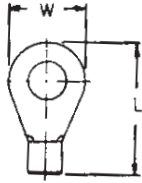

Catalog Number	Wire Range	Stud Size	Dimensions	
			L	W
44150-B10	4	10	1.30	.66
44151-B10	4	1/4	1.30	.66
44152-B10	4	5/16	1.30	.66
44153-B10	4	3/8	1.30	.66
44154-B10	4	7/16	1.30	.66
44155-B10	4	1/2	1.90	.88
44160-B10	2	10	1.55	.60
44161-B10	2	1/4	1.55	.60
44162-B10	2	5/16	1.55	.70
44163-B10	2	3/8	1.55	.70
44164-B10	2	7/16	1.55	.81
44165-B10	2	1/2	1.93	.81
44170-B2	1/0	1/4	1.93	.88
44171-B2	1/0	5/16	1.93	.88
44172-B2	1/0	3/8	1.93	.88
44173-B2	1/0	7/16	1.93	.88
44174-B2	1/0	1/2	1.93	.88

All wire sizes, unless noted otherwise, are American Wire Gauge (AWG)
Can be supplied in bulk. Consult factory for part number. UL File E158587

