

ILSCO Non-Insulated Ring Terminals

RoHS
Compliant

UL
LISTED
8M24




TYPE ILSCONS

Features

- Manufactured from high strength copper alloy
- Electro-tin plated
- Silver solder brazed seam
- Packaged in convenient small quantities
- UL Listed and CSA Certified, 90° C

Benefits

- Provides maximum conductivity
- Provides low contact resistance
- May be crimped anywhere and will not split open, even under extreme operating stresses
- Can be displayed on merchandise racks
- Ensures reliability for copper conductor

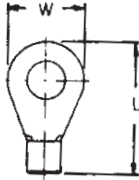

| Catalog Number | Wire Range | Stud Size | Dimensions | |
|----------------|------------|-----------|------------|------|
| | | | L | W |
| 44180-B2 | 2/0 | 1/4 | 1.93 | .88 |
| 44181-B2 | 2/0 | 5/16 | 1.93 | .88 |
| 44182-B2 | 2/0 | 3/8 | 1.93 | .88 |
| 44183-B2 | 2/0 | 7/16 | 1.93 | .88 |
| 44184-B2 | 2/0 | 1/2 | 1.93 | .88 |
| 44190-B2 | 3/0 | 1/4 | 1.97 | .93 |
| 44191-B2 | 3/0 | 5/16 | 1.97 | .93 |
| 44192-B2 | 3/0 | 3/8 | 1.97 | .93 |
| 44193-B2 | 3/0 | 7/16 | 1.97 | .93 |
| 44194-B2 | 3/0 | 1/2 | 1.97 | .93 |
| 44195-B2 | 4/0 | 5/16 | 2.17 | 1.08 |
| 44196-B2 | 4/0 | 3/8 | 2.17 | 1.08 |
| 44197-B2 | 4/0 | 7/16 | 2.17 | 1.08 |
| 44198-B2 | 4/0 | 1/2 | 2.17 | 1.08 |

All wire sizes, unless noted otherwise, are American Wire Gauge (AWG)

Can be supplied in bulk. Consult factory for part number.

UL File E158587