

ILSCO Vinyl Insulated Ring Terminals

RoHS
Compliant

UL
LISTED
8M24

CSA

TYPE ILSCONS


Features

- Color coded
- Manufactured from high strength copper alloy
- Electro-tin plated
- Vinyl insulation
- Packaged in convenient small quantities
- UL Listed and CSA Certified for 600 volts, 90° C

Benefits

- Provides easy wire range identification
#22-18 AWG Red
#16-14 AWG Blue
#12-10 AWG Yellow
- Provides maximum conductivity
- Provides low contact resistance
- Provides tough pliable insulative qualities to protect connectors and wire from corrosion as well as providing some strain relief
- Can be displayed on merchandise racks
- Ensures reliability for copper conductor

A1

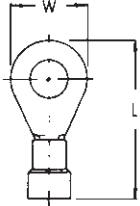

Catalog Number	Wire Range	Stud Size	Dimensions		Maximum Wire Insulated Diameter
			L	W	
44200-B10	18-22	4	.74	.22	.145
44201-B10	18-22	6	.91	.31	.145
44202-B10	18-22	8	.91	.31	.145
44203-B10	18-22	10	.91	.31	.145
44204-B10	18-22	1/4	1.10	.46	.145
44205-B10	18-22	5/16	1.14	.53	.145
44206-B10	18-22	3/8	1.14	.53	.145
44210-B10	14-16	4	.80	.25	.175
44211-B10	14-16	6	.88	.25	.175
44212-B10	14-16	8	.94	.31	.175
44213-B10	14-16	10	.94	.31	.175
44214-B10	14-16	1/4	1.06	.53	.175
44215-B10	14-16	5/16	1.06	.53	.175
44216-B10	14-16	3/8	1.06	.53	.175
44220-B10	10-12	6	.95	.28	.255
44221-B10	10-12	8	.95	.28	.255
44222-B10	10-12	10	1.00	.38	.255
44223-B10	10-12	1/4	1.22	.53	.255
44224-B10	10-12	3/8	1.33	.53	.255
44225-B10	10-12	7/16	1.46	.71	.255

All wire sizes, unless noted otherwise, are American Wire Gauge (AWG)

Can be supplied in bulk. Consult factory for part number.

UL File E158587



4730 Madison Road, Cincinnati, Ohio 45227-1426 Phone 513 533-6200 Fax 513 871-4084 Web site www.ilsco.com
Canada 1050 Lakeshore Road East, Mississauga, Ontario, Canada L5E1E4 Phone 905 274-2341 Fax 905 274-8763