

TYPE ILSCONS


Features

- Manufactured from high strength steel alloy
- Electro-tin plated
- Silver solder brazed seam
- Packaged in convenient small quantities
- 900° F 482° C Continuous, 1200° F 649° C Intermittent

Benefits

- Provides maximum conductivity
- Provides low contact resistance
- May be crimped anywhere and will not split open, even under extreme operating stresses
- Can be displayed on merchandise racks

A1

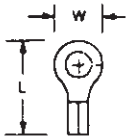

Catalog Number	Wire Range	Stud Size	Dimensions	
			L	W
44300-B20	18-22	4-6	.65	.25
44301-B20	18-22	8-10	.69	.31
44302-B20	18-22	12-1/4	.93	.56
44310-B20	14-16	4-6	.65	.25
44311-B20	14-16	8-10	.69	.31
44312-B20	14-16	12-1/4	.90	.46
44320-B20	10-12	4-6	.67	.28
44321-B20	10-12	8-10	.72	.37
44322-B20	10-12	12-1/4	.93	.53
44323-B20	10-12	5/16-3/8	.99	.60
44330-B10	8	12-1/4	.95	.47
44340-B10	6	5/16-3/8	1.22	.63

All wire sizes, unless noted otherwise, are American Wire Gauge (AWG)
Can be supplied in bulk. Consult factory for part number.