

TYPE ILSCONS


Features

- Manufactured from high strength copper alloy
- Electro-tin plated
- Silver solder brazed seam
- Packaged in convenient small quantities
- UL Listed and CSA Certified, 90° C

Benefits

- Provides maximum conductivity
- Provides low contact resistance
- May be crimped anywhere and will not split open, even under extreme operating stresses
- Can be displayed on merchandise racks
- Ensures reliability for copper conductor

A1

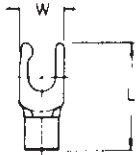

Catalog Number	Wire Range	Stud Size	Dimensions	
			L	W
44400-B20	18-22	4	.68	.25
44401-B20	18-22	6	.68	.25
44402-B20	18-22	8	.68	.30
44403-B20	18-22	10	.68	.32
44410-B20	14-16	4	.68	.25
44411-B20	14-16	6	.68	.25
44412-B20	14-16	8	.68	.25
44413-B20	14-16	10	.68	.30
44414-B20	14-16	1/4	.90	.32
44420-B20	10-12	6	.73	.28
44421-B20	10-12	8	.73	.32
44422-B20	10-12	10	.73	.32
44423-B20	10-12	1/4	.94	.43

All wire sizes, unless noted otherwise, are American Wire Gauge (AWG)

Can be supplied in bulk. Consult factory for part number.

UL File E158587