

# ILSCO Vinyl Insulated Fork Terminals

RoHS  
Compliant

UL  
LISTED  
8M24

CSA



## TYPE ILSCONS

### Features

- Color coded
- Manufactured from high strength copper alloy
- Electro-tin plated
- Vinyl insulation
- Packaged in convenient small quantities
- UL Listed and CSA Certified for 600 volts, 90° C

### Benefits

- Provides easy wire range identification  
#22-18 AWG Red  
#16-14 AWG Blue  
#12-10 AWG Yellow
- Provides maximum conductivity
- Provides low contact resistance
- Provides tough pliable insulative qualities to protect connectors and wire from corrosion as well as providing some strain relief
- Can be displayed on merchandise racks
- Ensures reliability for copper conductor

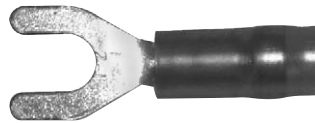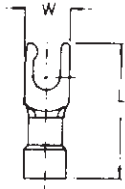

A1

Catalog Number	Wire Range	Stud Size	Dimensions		Maximum Wire Insulated Diameter
			L	W	
44500-B10	18-22	4	.88	.25	.145
44501-B10	18-22	6	.88	.29	.145
44502-B10	18-22	8	.88	.31	.145
44503-B10	18-22	10	.88	.31	.145
44511-B10	14-16	6	.88	.29	.175
44512-B10	14-16	8	.88	.31	.175
44513-B10	14-16	10	.88	.31	.175
44514-B10	14-16	1/4	1.10	.43	.175
44520-B10	10-12	6	1.06	.28	.255
44521-B10	10-12	8	1.06	.28	.255
44522-B10	10-12	10	1.06	.28	.255
44523-B10	10-12	1/4	1.24	.43	.255
45322FL-P100*	14-16	6	.88	.29	.175
45323FL-P100*	14-16	8	.88	.31	.175
45324FL-P100*	14-16	10	.88	.31	.175
45423FL-P50*	10-12	8	1.06	.28	.255
45424FL-P50*	10-12	10	1.06	.28	.255

All wire sizes, unless noted otherwise, are American Wire Gauge (AWG)

\* Flanged Fork

Can be supplied in bulk. Consult factory for part number.

UL File E158587

