


SCREW: NONE
CAT. NO.: SEE CHART
INFORMATION SHEET: FORM 157

MATERIAL: COPPER
PLATING: EL-TIN
MARKING: SEE BELOW


REV: H
DRAWN BY: DW
DATE: 7/19/2007
SCALE: 2:1
SIZE: B



DWG NO: Y0503-D
SHEET: 1 OF 1

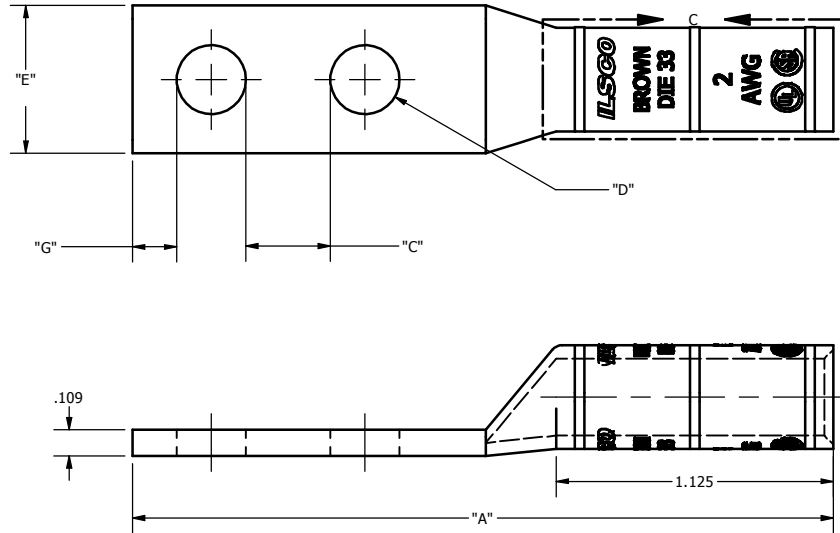

DETAIL C
TOP & BOTTOM INK MARKING

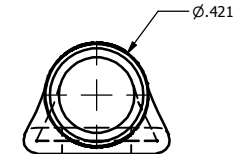

CATALOG NUMBER	"A"	"B"	"C"	"D"	"E"	"F"	TANG MARKING
CLND-2-10-12	2.661	0.281	0.219	0.599	0.148		ILSCO, C-2-516-34, 5/16 X 3/4, 2 AWG, DIE 33, UL, CSA
CLND-2-10-58	2.661	0.406	0.219	0.599	0.148		
CLND-2-10-1116	2.661	0.468	0.219	0.599	0.148		
CLND-2-10-34	2.848	0.531	0.219	0.599	0.148		ILSCO, CLND-2-10-34, 10 X 3/4, 2 AWG, DIE 33, UL, CSA
CLND-2-10-1	3.098	0.781	0.219	0.599	0.148		ILSCO, CLND-2-10-1, 10 X 1, DIE 33, 2 AWG, UL, CSA
CLND-2-14-12	2.661	0.219	0.281	0.599	0.180		
CLND-2-14-58	2.848	0.344	0.281	0.599	0.180		ILSCO, CLND-2-14-58, 1/4 X 5/8, 2 AWG, DIE 33, UL, CSA
CLND-2-14-34	2.848	0.469	0.281	0.599	0.180		ILSCO, CLND-2-14-34, 1/4 X 3/4, 2 AWG, DIE 33, UL, CSA
CLND-2-14-1	3.098	0.719	0.281	0.599	0.180		ILSCO, C-2-14-1, 1/4 X 1, 2 AWG, DIE 33, UL, CSA
CLND-2-516-58	2.848	0.282	0.343	0.599	0.180		ILSCO, C-2-516-58, 5/16 X 5/8, 2 AWG, DIE 33, UL, CSA
CLND-2-516-34	3.098	0.407	0.343	0.599	0.180		ILSCO, C-2-516-34, 5/16 X 3/4, 2 AWG, DIE 33, UL, CSA
CLND-2-516-78	3.098	0.532	0.343	0.599	0.180		
CLND-2-516-1	3.348	0.657	0.343	0.599	0.180		ILSCO, C-2-516-1, 5/16 X 1, 2 AWG, DIE 33, UL, CSA
CLND-2-516-134	3.911	1.407	0.343	0.599	0.180		ILSCO, CLND-2-516-134, 5/16 X 1-3/4, 2 AWG, DIE 33, UL, CSA
CLND-2-38-34	3.098	0.344	0.406	0.599	0.211		ILSCO, C-2-38-34, 3/8 X 3/4, 2 AWG, DIE 33, UL, CSA
CLND-2-38-78	3.348	0.469	0.406	0.599	0.211		ILSCO, C-2-38-78, 3/8 X 7/8, 2 AWG, DIE 33, UL, CSA
CLND-2-38-1	3.348	0.594	0.406	0.599	0.211		ILSCO, CLND-2-38-1, 3/8 X 1, 2 AWG, DIE 33, UL, CSA
CLND-2-38-116	3.348	0.656	0.406	0.599	0.211		
CLND-2-38-118	3.536	0.719	0.406	0.599	0.211		
CLND-2-38-134	4.036	1.344	0.406	0.599	0.211		ILSCO, CLND-2-38-134, 3/8 X 1-3/4, DIE 33, 2 AWG, UL, CSA
CLND-2-38-2	4.411	1.594	0.406	0.599	0.211		
CLND-2-12-1	3.536	0.438	0.562	.744	0.265		
CLND-2-12-114	3.911	0.688	0.562	.744	0.265		
CLND-2-12-112	4.036	0.938	0.562	.744	0.265		
CLND-2-12-134	4.411	1.188	0.562	.744	0.265		ILSCO, CLND-2-12-134, 1/2 X 1-3/4, 2 AWG, DIE 33, UL, CSA
CLND-2-12-178	4.411	1.313	0.562	.744	0.265		

THE INFORMATION CONTAINED WITHIN THIS DOCUMENT IS PROPRIETARY TO ILSCO AND MAY NOT BE DISCLOSED WITHOUT PRIOR WRITTEN CONSENT