

Surge Strip Protection Device - Surge Protective Device, Point-of-use strip, White, 3-Mode, 6 Outlets, 125 VAC, Type 3, Connected Equipment Warranty 5 yr \$25,000

Item IG206153



PRODUCT DESCRIPTION

Type 3 Point-of-Use Surge Protective Devices (SPD) are designed for heavy industrial use with 3 modes of surge protection (L-N, L-G, N-G). Features a 15 A resettable breaker and #14 AWG SJT power cord with molded plug. CSA certified to ANSI/UL 1449, 3rd Edition.

FEATURES

- ▶ Three Modes of protection
- ▶ Metal Oxide Varistor (MOV) surge protection technology
- ▶ 15 A resettable breaker
- ▶ #14 AWG SJT power cord with molded plug
- ▶ Fifteen foot cord with six outlets
- ▶ LED protection indicator
- ▶ EMI/RFI Noise Filtration
- ▶ Extruded aluminum housing
- ▶ White
- ▶ 5-year product warranty

APPLICATIONS

- ▶ Surge Protection

TECHNICAL DATA

General	
Model Number	IG206153
Description	Surge Protective Device, Point-of-use strip, White, 3-Mode, 6 Outlets, 125 VAC, Type 3, Connected Equipment Warranty 5 yr \$25,000
UPC Code	078275124585
Brand	Intermatic
Country of Origin (Intermatic)	MEXICO
Warranty Period	5-Year limited
Connected Equipment Warranty Period	5-Year
Control Specifications	
Surge Protection Type	3
Mechanical Specifications	
Number of Outlets	6
Dimensions	
Product Dimensions (H x W x D) in	1 7/8 x 1 7/8 x 15 3/4 in
Cord Length (ft)	15
Cord Length (m)	4.572
Material Specifications	
Color	White

Electrical Specifications

Maximum Continuous Operating Voltage (L-G)	130
Maximum Continuous Operating Voltage (L-N)	130
Maximum Continuous Operating Voltage (N-G)	130
Voltage Protection Rating (L-N)	400
Circuit Breaker Amperage	15 A
Voltage Protection Rating (L-G)	400
Surge Protection Technology	MOV
Voltage Protection Rating (N-G)	500
Has EMI/RFI Noise Filtration	Yes

Packaging

Shipping Weight (lbs)	3.493
Unit Carton Dimensions (H x W x L) in	3 x 5 x 16.5 in


Environmental Specifications

Temperature (operation)	-4 °F to 104 °F / (-20 °C to 40 °C)
-------------------------	-------------------------------------

Standards and Certifications

CSA Certification	cCSAus
UL Standard	Ansi/UL 1449 3rd Edition
California Proposition 65	DEHP

DRAWINGS AND DIAGRAMS

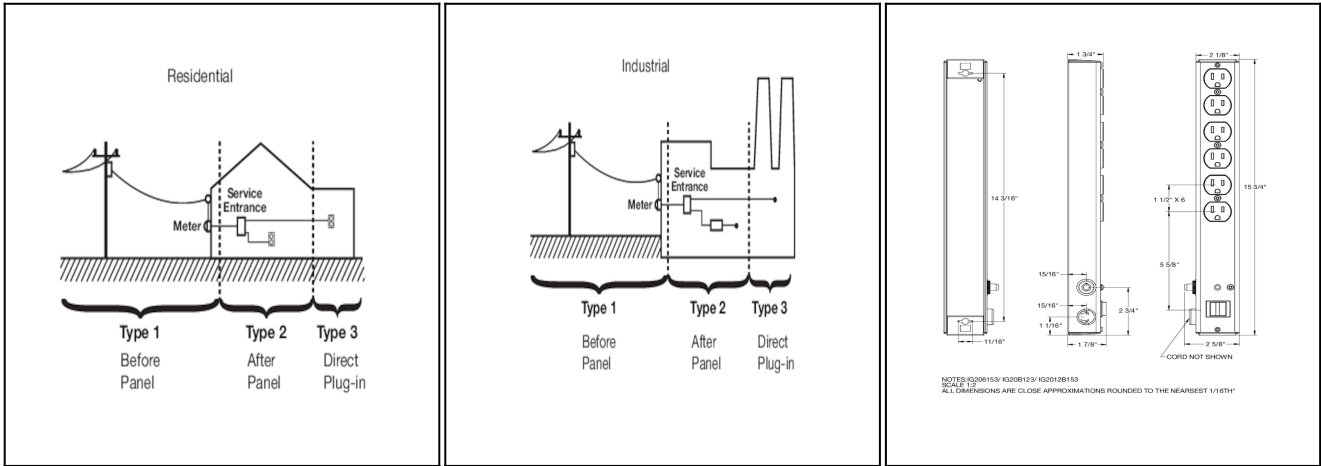

ACCESSORIES



24EG5133

Mounting Bracket Plate for Type 3 SPD Surge Strips