



# PIR Vacancy Sensor Switch

*for electronic ballasts*



IDS-DPBIF2-IV

IDS-DPBIF2-WH

## Features:



- Manual ON only with automatic OFF after time delay expires
- Manual OFF option
- For use with electronic fluorescent ballasts
- Adjustable time delay ranging from 15 seconds to 30 minutes.
- Passive Infrared Technology
- Adjustable sensitivity settings
- Standard decorator wall plate included
- ISO9001 Registered manufacturing facility
- Meets California Title 24 Requirements
- UL/cUL Listed device
- Five Year Limited Warranty



## *Ideal for:*

Offices, Copy Rooms, Break Rooms  
Storage Closets, Small Restrooms,  
Small Conference Rooms,  
Maintenance Closets



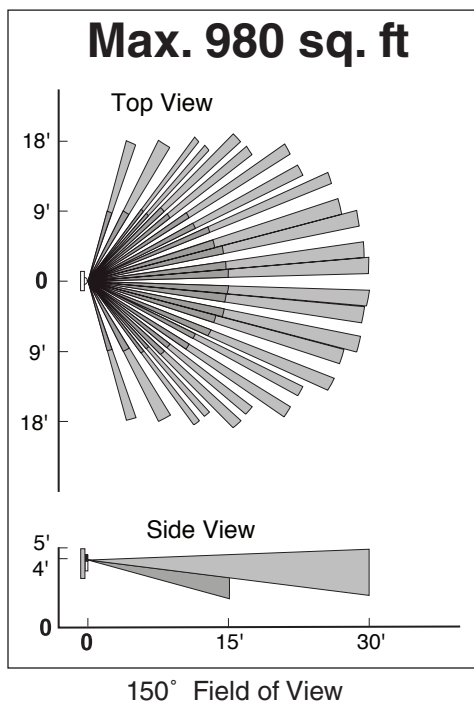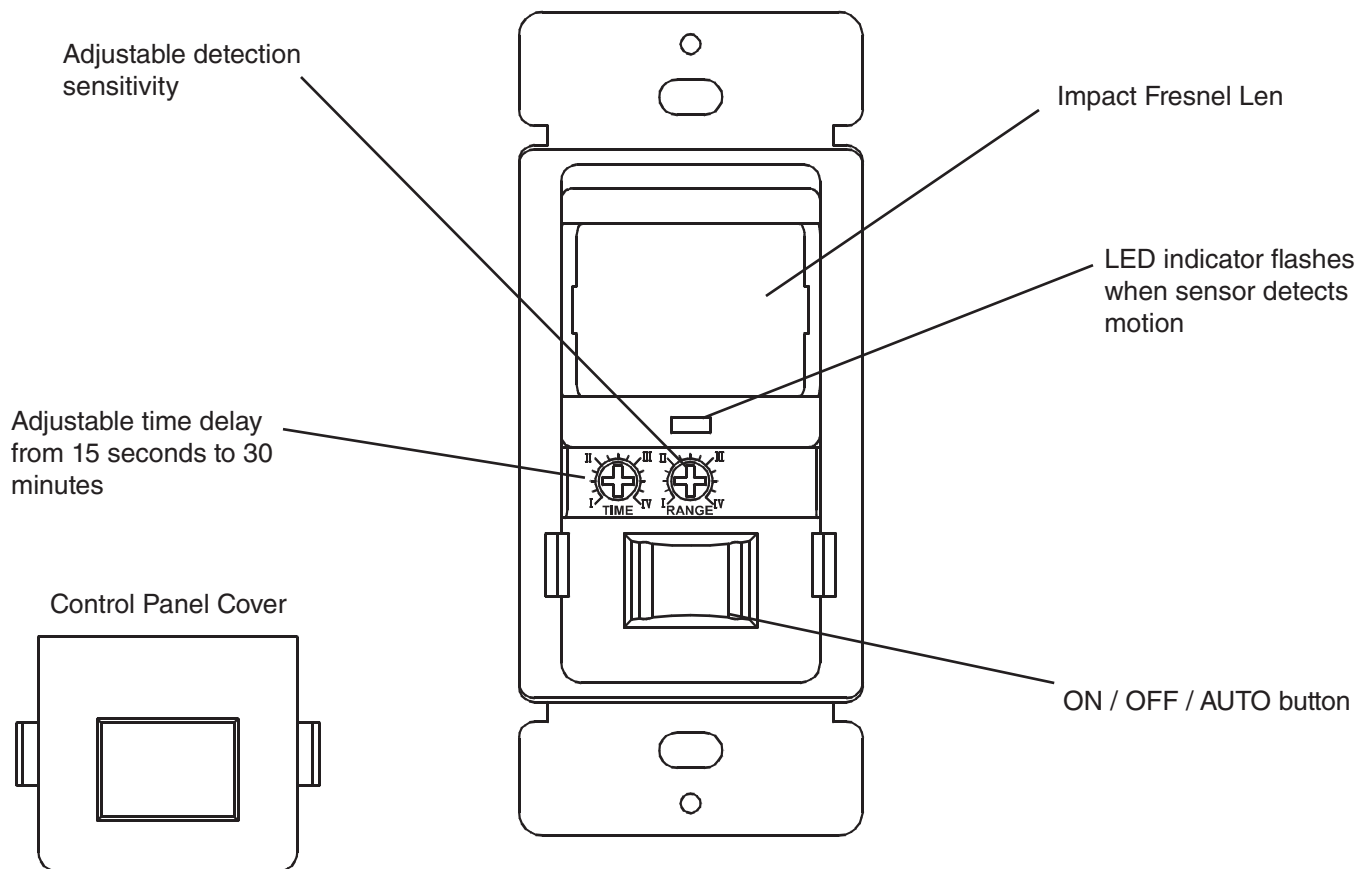

|                                   |                                                                                                                                                                                                                                                                                |
|-----------------------------------|--------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| <b>Part #</b>                     | <b>IOS-DPBIF2</b>                                                                                                                                                                                                                                                              |
| <b>Desc</b>                       | Single Pole, Decorator Wall Switch<br>PIR Vacancy Sensor for electronic ballasts                                                                                                                                                                                               |
| <b>Rating</b>                     | Incandescent / Tungsten: 25W-500W-120VAC.<br>Fluorescent / Ballast: 500VA-120VAC<br>Motor: 1/8HP-120VAC<br>Time Delay: 15 Sec to 30 Min<br>Operation Temperature: 32°F--131°F / 0-55°C<br>No minimum Load required.<br><b>Can be used with electronic fluorescent ballasts</b> |
| <b>Coverage</b>                   | 150° , 980sq. ft                                                                                                                                                                                                                                                               |
| <b>Color</b>                      | White, Ivory                                                                                                                                                                                                                                                                   |
| <b>Five Year Limited Warranty</b> |                                                                                                                                                                                                                                                                                |

### Model Ordering Info:

| Series                            | Style              | — | Type           | Operation                     | — | Finish    |
|-----------------------------------|--------------------|---|----------------|-------------------------------|---|-----------|
| <b>IOS</b>                        | <b>D</b>           |   | <b>PB</b>      | <b>IF2</b>                    |   | <b>WH</b> |
| Intermatic<br>Occupancy<br>Sensor | Decorator<br>Plate |   | Push<br>Button | Incandescent /<br>Fluorescent |   | White     |

**IV**  
Ivory