


C.



D.

## R8800 and T8800 Series Sprinkler/Irrigation Time Switches with 14-Day Skipper

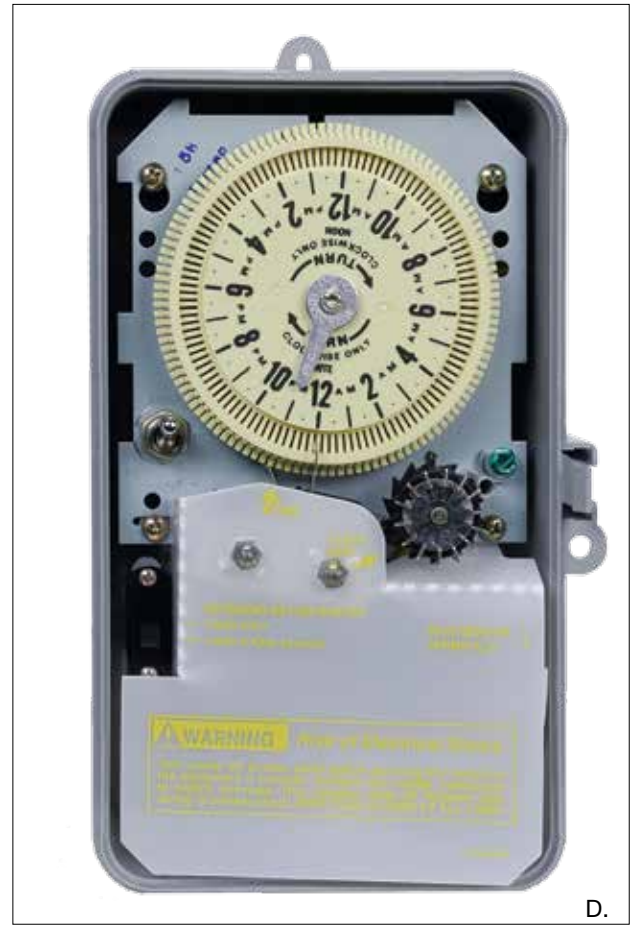

- Up to 44 ON/OFF settings per day
- Water metering increments from 12 minutes to 20 hours and 45 minutes
- 14-Day Skipper enables irrigation to be omitted on selected day(s)
- Provides for “every other” day operation
- ON/OFF/AUTOMATIC switch enables shutdown during rainy days and extended watering during dry periods without disturbing the cycle set on dial

### Mechanism Only

Model #	Switch	Clock Motor Voltage	Load Voltage	Amps (per pole)	HP
T8805M101C	SPST	120 VAC, 60 Hz	120 VAC, 60 Hz	15	½
C. R8806M101C	DPST	240 VAC, 60 Hz	240 VAC, 60 Hz	25	2

### Plastic Type 3R Enclosure

Model #	Switch	Clock Motor Voltage	Load Voltage	Amps (per pole)	HP
D. T8805P101C	SPST	120 VAC, 60 Hz	120 VAC, 60 Hz	15	½
R8806P101C	DPST	240 VAC, 60 Hz	240 VAC, 60 Hz	25	2
R8815P101C*	DPST	120 VAC, 60 Hz	120 VAC, 60 Hz	25	1½
R8816P101C*	DPST	240 VAC, 60 Hz	240 VAC, 60 Hz	30	3
T8845PV**	SPST	120 VAC, 60 Hz	24 VAC, 60 Hz	20 VA	-

\*Rain sensor enabled (rain sensor not included)

\*\*Includes 24 Volt, 20VA transformer

**Ratings:**  
**Operating Temperature:** -40°F to 130°F (-40°C to 54°C)  
**Warranty:** 1 year

For additional trippers (156T1950A), see page 153  
 For replacement switch (133T700A), see page 153  
 For additional skipper pins (156T1954A), see page 153  
 For enclosure dimensions, see page 146