



NEMA 4X / IP66 & NEMA 12 / IP55 Enclosed Drives

6 Frame Sizes
↑ 250HP



Energy efficient fan and pump control


- ✓ ECO Vector Motor Control
- ✓ Energy Optimised Design
- ✓ Internal EMC Filter
- ✓ Low Noise Operation

Optistick Smart
Rapid commissioning tool



	Frame	HP	Amps	MODEL CODE	Product Family	Cancellation	Frame Size	Voltage Code	Output Current 10	Supply Phases	EMC Filter	Brake Resistor	Enclosure Option	Nema XX Switched D	List Price	Nema MX Keypad Only X	List Price	Nema 12 Enclosed	List Price
200 - 240 Volt +/- 10% 1 Phase Input	2	1	4.3	ODV - 3 - 2 2 0043 - 1	F	1	#-TN	\$1,970.00	\$1,790.00										
	2	2	7	ODV - 3 - 2 2 0070 - 1	F	1	#-TN	\$2,060.00	\$1,875.00										
	2	3	10.5	ODV - 3 - 2 2 0105 - 1	F	1	#-TN	\$2,150.00	\$1,970.00										
200 - 240 Volt +/- 10% 3 Phase Input	2	1	4.3	ODV - 3 - 2 2 0043 - 3	F	1	#-TN	\$2,125.00	\$1,945.00										
	2	2	7	ODV - 3 - 2 2 0070 - 3	F	1	#-TN	\$2,310.00	\$2,100.00										
	2	3	10.5	ODV - 3 - 2 2 0105 - 3	F	1	#-TN	\$2,480.00	\$2,300.00										
	3	5	18	ODV - 3 - 3 2 0180 - 3	F	1	#-TN	\$3,700.00	\$3,530.00										
	3	7.5	24	ODV - 3 - 3 2 0240 - 3	F	1	#-TN	\$4,110.00	\$3,940.00										
	4	10	30	ODV - 3 - 4 2 0300 - 3	F	1	N-TN		\$4,445.00										
	4	15	46	ODV - 3 - 4 2 0460 - 3	F	1	N-TN		\$4,795.00										
	5	20	61	ODV - 3 - 5 2 0610 - 3	F	1	N-TN		\$6,130.00										
	5	25	72	ODV - 3 - 5 2 0720 - 3	F	1	N-TN		\$7,065.00										
	5	30	90	ODV - 3 - 5 2 0900 - 3	F	1	N-TN		\$8,410.00										
	6	40	110	ODV - 3 - 6 2 1100 - 3	F	1	N-TN		\$10,345.00										
	6	50	150	ODV - 3 - 6 2 1500 - 3	F	1	N-TN		\$14,475.00										
	6	60	180	ODV - 3 - 6 2 1800 - 3	F	1	N-TN		\$17,230.00										
	7	75	202	ODV - 3 - 7 2 2020 - 3	F	1	N-TN		\$21,365.00										
7	100	240	ODV - 3 - 7 2 2400 - 3	F	1	N-TN		\$24,810.00											
380 - 480 Volt +/- 10% 3 Phase Input	2	1	2.2	ODV - 3 - 2 4 0022 - 3	F	1	#-TN	\$2,025.00	\$1,855.00										
	2	2	4.1	ODV - 3 - 2 4 0041 - 3	F	1	#-TN	\$2,180.00	\$2,000.00										
	2	3	5.8	ODV - 3 - 2 4 0058 - 3	F	1	#-TN	\$2,315.00	\$2,155.00										
	2	5	9.5	ODV - 3 - 2 4 0095 - 3	F	1	#-TN	\$2,480.00	\$2,300.00										
	3	7.5	14	ODV - 3 - 3 4 0140 - 3	F	1	#-TN	\$3,390.00	\$3,220.00										
	3	10	18	ODV - 3 - 3 4 0180 - 3	F	1	#-TN	\$3,700.00	\$3,530.00										
	3	15	24	ODV - 3 - 3 4 0240 - 3	F	1	#-TN	\$4,110.00	\$3,940.00										
	4	20	30	ODV - 3 - 4 4 0300 - 3	F	1	N-TN		\$4,445.00										
	4	25	39	ODV - 3 - 4 4 0390 - 3	F	1	N-TN		\$4,795.00										
	4	30	46	ODV - 3 - 4 4 0460 - 3	F	1	N-TN		\$5,170.00										
	5	40	61	ODV - 3 - 5 4 0610 - 3	F	1	N-TN		\$6,615.00										
	5	50	72	ODV - 3 - 5 4 0720 - 3	F	1	N-TN		\$7,235.00										
	5	60	90	ODV - 3 - 5 4 0900 - 3	F	1	N-TN		\$8,410.00										
	6	75	110	ODV - 3 - 6 4 1100 - 3	F	1	N-TN		\$10,345.00										
	6	100	150	ODV - 3 - 6 4 1500 - 3	F	1	N-TN		\$12,405.00										
	6	150	180	ODV - 3 - 6 4 1800 - 3	F	1	N-TN		\$17,230.00										
	7	175	202	ODV - 3 - 7 4 2020 - 3	F	1	N-TN		\$21,365.00										
7	200	240	ODV - 3 - 7 4 2400 - 3	F	1	N-TN		\$24,810.00											
7	250	302	ODV - 3 - 7 4 3020 - 3	F	1	N-TN		\$27,535.00											
500 - 600 Volt +/- 10% 3 Phase Input	2	1	2.1	ODV - 3 - 2 6 0021 - 3	O	1	#-TN	\$2,235.00	\$2,125.00										
	2	2	3.1	ODV - 3 - 2 6 0031 - 3	O	1	#-TN	\$2,400.00	\$2,295.00										
	2	3	4.1	ODV - 3 - 2 6 0041 - 3	O	1	#-TN	\$2,550.00	\$2,465.00										
	2	5	6.5	ODV - 3 - 2 6 0065 - 3	O	1	#-TN	\$2,720.00	\$2,640.00										
	2	7.5	9	ODV - 3 - 2 6 0090 - 3	O	1	#-TN	\$2,955.00	\$2,930.00										
	3	10	12	ODV - 3 - 3 6 0120 - 3	O	1	#-TN	\$3,730.00	\$3,840.00										
	3	15	17	ODV - 3 - 3 6 0170 - 3	O	1	#-TN	\$4,075.00	\$4,045.00										
	4	20	22	ODV - 3 - 4 6 0220 - 3	O	1	N-TN		\$5,315.00										
	4	25	28	ODV - 3 - 4 6 0280 - 3	O	1	N-TN		\$5,860.00										
	4	30	34	ODV - 3 - 4 6 0340 - 3	O	1	N-TN		\$6,350.00										
	4	40	43	ODV - 3 - 4 6 0430 - 3	O	1	N-TN		\$6,920.00										
	5	50	54	ODV - 3 - 5 6 0540 - 3	O	1	N-TN		\$8,010.00										
	5	60	65	ODV - 3 - 5 6 0650 - 3	O	1	N-TN		\$9,320.00										
	6	75	78	ODV - 3 - 6 6 0780 - 3	O	1	N-TN		\$13,665.00										
	6	100	105	ODV - 3 - 6 6 1050 - 3	O	1	N-TN		\$16,395.00										
	6	125	130	ODV - 3 - 6 6 1300 - 3	O	1	N-TN		\$17,705.00										
6	150	150	ODV - 3 - 6 6 1500 - 3	O	1	N-TN		\$19,305.00											

Enclosure & Display Types

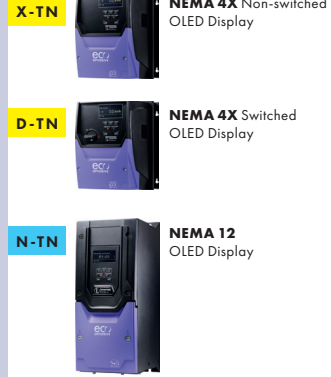

- F** Internal EMC Filter
- O** No Internal EMC Filter
- 1** No Internal Brake

NOT TO SCALE



Size	IP66		IP55			
	2	3	4	5	6	7
in Height	10.1	12.2	17.7	21.2	34.1	50.4
in Width	7.4	8.3	6.7	9.3	13.0	13.0
in Depth	9.4	10.5	9.9	11.0	13.0	14.2
lb Weight	10.6	17.0	25.4	50.7	121.3	196.2

Contact us to discuss availability & pricing