

# Panel Mount Receptacles

## Ordering Information

### Flange mount

		Male	Female
Style I	2 pole	5000108-2	5000108-28
	3 pole	5000109-2	5000109-28
	4 pole	5000110-2	5000110-28
	5 pole	5000111-2	5000111-28
	6 pole	5000120-2	5000120-28
Style II	6 pole	X8987-22	X8987-39
	7 pole	X8988-22	X8988-39
	8 pole	X8989-22	X8989-39


### 1/2" - 14NPT

		Female
Style I	2 pole	5000108-30
	3 pole	5000109-30
	4 pole	5000110-30
	5 pole	5000111-30




Mini-Line panel mount receptacles.

## Dimensions for flange mount

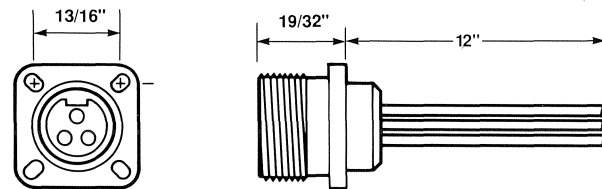

# Accessories

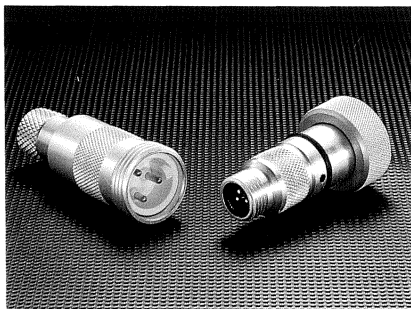



Mini-Line to Micro-Mini and Micro-Mini to Mini-Line adaptors

## Ordering Information

### Adaptors

	Female Mini to Male Micro	Female Micro to Male Mini
2 pole	5000108-1	5000113-35
3 pole	5000109-1	5000114-35
4 pole	5000110-1	5000115-35
5 pole	5000111-1	5000116-35

## Dimensions

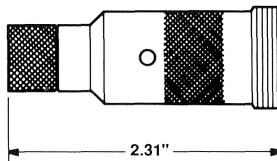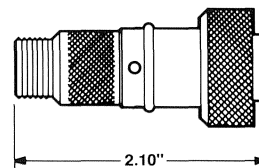

Closure caps and adaptor for joining portable cordsets

### Adaptor for joining portable cordsets

Style	Metal	Plastic
I	1316511	600216-2
II	1316964	600507-4
III	1317142	

### Closure Caps (Metal)

Style	Plugs	Receptacles
I	3316582-2	3316582-1
II	3316966	3316965
III	3317071-1	3317071

### Closure Caps (Plastic)

Style	Plugs	Receptacles
I	A600196-6	A600196-2
II	A600494-4	A600494-3