

Cam-Lok® “J” Power Series



All Cam-Lok part numbers available in convenient, single-use, color-coded packaging.

RECEPTACLES		MALE	
COLOR	CABLE SIZE	90° COMPLETE PART NO.	30° COMPLETE PART NO.
BLACK	350-750MCM	E1017-1600	E1017-1601
RED		E1017-1604	E1017-1605
GREEN		E1017-1608	E1017-1609
WHITE		E1017-1610	E1017-1611
BLUE		E1017-1612	E1017-1613
BROWN		E1017-1614	E1017-1615
ORANGE		E1017-1606	E1017-1607
YELLOW		E1017-1602	E1017-1603



E1017-1604


RECEPTACLES		FEMALE	
COLOR	CABLE SIZE	90° COMPLETE PART NO.	30° COMPLETE PART NO.
BLACK	350-750MCM	E1017-1625	E1017-1626
RED		E1017-1629	E1017-1630
GREEN		E1017-1633	E1017-1634
WHITE		E1017-1635	E1017-1636
BLUE		E1017-1637	E1017-1638
BROWN		E1017-1641	E1017-1642
ORANGE		E1017-1631	E1017-1632
YELLOW		E1017-1627	E1017-1628



E1017-1637

E1017 Series

Stud size 1/2" - 13, maximum torque 40 ft. lbs.

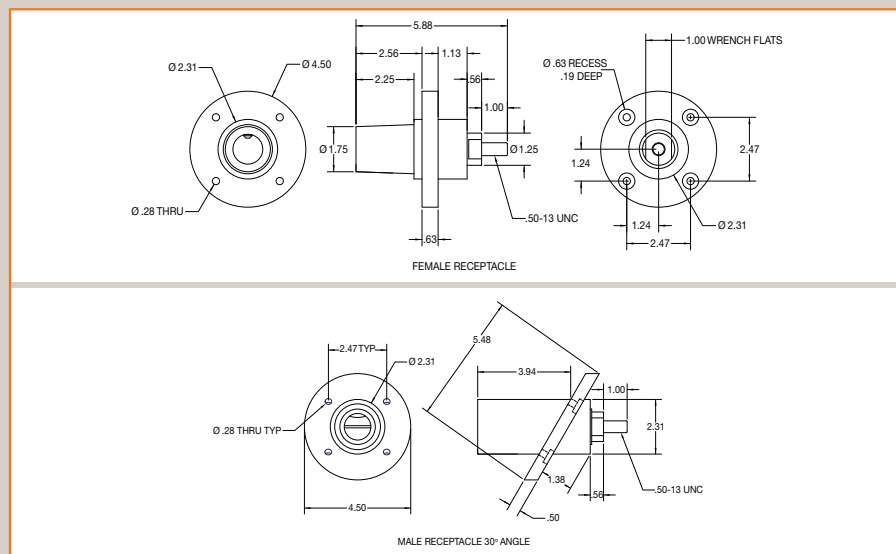

CAM-LOK “J” POWER SERIES
RECEPTACLES AND PLUGS PROVIDE THE MEANS TO QUICKLY CONNECT AND DISCONNECT POWER SYSTEMS SAFELY AT CONCERTS AND CARNIVALS AS WELL AS CONNECTING GENERATORS, STANDBY POWER, AND LOAD TESTING IN HOSPITALS, UTILITIES AND HEAVY INDUSTRIAL ENVIRONMENTS.

RATINGS: 600 Volts UP to 690 AMPERES CONTINUOUS

STANDARD MATERIALS
CABLE SIZE: 350 - 750 MCM
CONNECTOR BODY: SYNTHETIC RUBBER
CONTACT: BRASS

AGENCY APPROVALS
UL LISTED E67181
CSA CERTIFIED LR13963

ENVIRONMENTAL RATING: NEMA 3R