








DISTRIBUTION



EXBLI/EXBSPI SERIES

IEC CIRCUIT BREAKER PANELBOARDS

Catalog Logic – for basic IEC Panelboard Enclosures

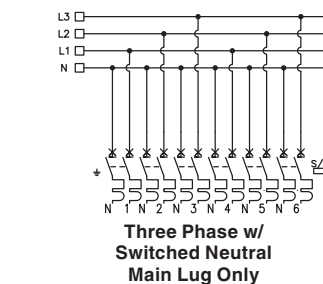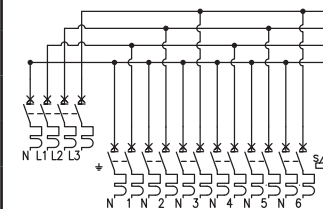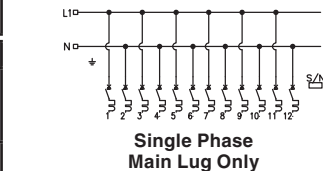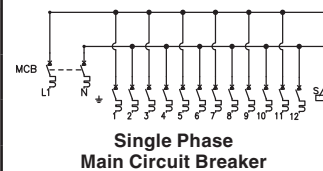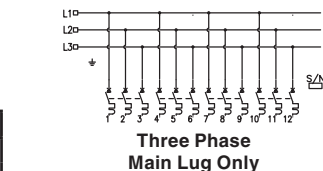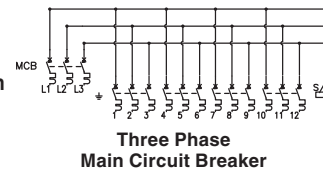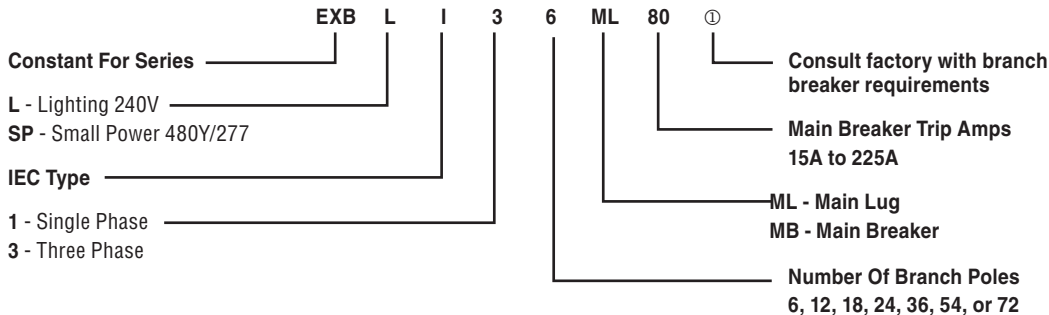

EXB DIMENSIONS MAIN BREAKER														
CATALOG NUMBER	# OF CIRCUITS W/MAIN BREAKER	STD CONDUITS AT BOTTOM (NPT)		QTY B RH SIDE	EXTERNAL DIMENSION (NI)			MOUNTING DIMENSIONS (INCHES)					LBS (KG)	
		A	B		F	G	H	I	J	K	L	M		
EXB-12126 N34	6	1-1/2"	3/4"	3	—	16.38 (416)	13.38 (340)	8.69 (221)	6.94 (176)	6.94 (176)	14.94 (379)	14.94 (379)	0.25 (6)	112 (50.80)
EXB-14146 N34	12	1-1/2"	3/4"	6	—	19.25 (489)	19.25 (489)	9.40 (239)	9.00 (229)	9.00 (229)	17.00 (432)	17.00 (432)	0.25 (6)	160 (72.57)
EXB-16166 N34	18	1-1/2"	3/4"	9	—	20.38 (518)	20.38 (518)	9.19 (233)	10.94 (278)	10.94 (278)	18.94 (481)	18.94 (481)	0.25 (6)	195 (88.45)
EXB-18186 N34	24	1-1/2"	3/4"	12	—	23.25 (591)	23.25 (591)	10 (254)	13.38 (340)	13.38 (340)	21.38 (543)	21.38 (543)	0.25 (6)	256 (116.12)
EXB-18248 N34	36	1-1/2"	3/4"	18	—	22.38 (568)	28.38 (721)	11.75 (298)	13 (330)	19 (483)	21 (533)	27 (686)	0.25 (6)	290 (131.54)
EXB-18368 N34	54	2-1/2"	3/4"	20	7	22.38 (568)	40.38 (1026)	12.38 (314)	13.25 (337)	31.5 (800)	21 (533)	39.5 (1003)	0.25 (6)	440 (199.58)
EXB-24368 N34	72	2-1/2"	3/4"	30	6	29.25 (743)	41.25 (1048)	12.4 (315)	19.56 (497)	31.56 (802)	27.56 (700)	39.56 (1005)	0.25 (6)	560 (254.01)

EXB DIMENSIONS MAIN LUG ONLY														
CATALOG NUMBER	# OF CIRCUITS MAIN LUG ONLY	STD CONDUITS AT BOTTOM (NPT)		QTY B RH SIDE	EXTERNAL DIMENSION (NI)			MOUNTING DIMENSIONS (INCHES)					LBS (KG)	
		A	B		F	G	H	I	J	K	L	M		
EXB-8106 N34	6	1-1/2"	3/4"	3	—	12.32 (313)	14.32 (364)	8.32 (211)	N/A	8.00 (203)	9.88 (251)	N/A	0.25 (6)	112 (50.80)
EXB-8126 N34	12	1-1/2"	3/4"	6	—	13.25 (337)	17.25 (438)	8.70 (221)	3.82 (97)	7.82 (199)	10.38 (264)	14.38 (365)	0.25 (6)	160 (72.57)
EXB-12186 N34	18	1-1/2"	3/4"	9	—	16.38 (416)	22.38 (568)	9.06 (230)	6.94 (176)	12.88 (327)	14.94 (379)	20.88 (530)	0.25 (6)	195 (88.45)
EXB-12186 N34	24	1-1/2"	3/4"	12	—	16.38 (416)	22.38 (568)	9.06 (230)	6.94 (176)	12.88 (327)	14.94 (379)	20.88 (530)	0.25 (6)	256 (116.12)
EXB-18186 N34	36	1-1/2"	3/4"	16	2	23.25 (591)	23.25 (591)	10 (254)	13.38 (340)	13.38 (340)	21.38 (543)	21.38 (543)	0.25 (6)	290 (131.54)
EXB-18368 N34	54	2-1/2"	3/4"	20	7	22.38 (568)	40.38 (1026)	12.38 (314)	13.25 (337)	31.5 (800)	21 (533)	39.5 (1003)	0.25 (6)	440 (199.58)
EXB-24368 N34	72	2-1/2"	3/4"	18	18	29.25 (743)	41.25 (1048)	12.4 (315)	19.56 (497)	31.56 (802)	27.56 (700)	39.56 (1005)	0.25 (6)	560 (254.01)

