



EXB and XJB Series Mounting Pans Ordering Instructions

Select proper mounting pan based on inside (length & width) of box. Order and price as separate item from junction box catalog number.


EXAMPLE: XJB-164812 } assemble
7995-5

EXB and XJB Series boxes have cast bosses which are drilled and tapped for direct mounting when pans are ordered.

Mounting pans are 1/8" or 3-16" thick sheet aluminum and are sized to provide the maximum usable surface area when installed.

All EXB-XJB series boxes have internal bosses that are factory machined to accept mounting pans.

Dimensions

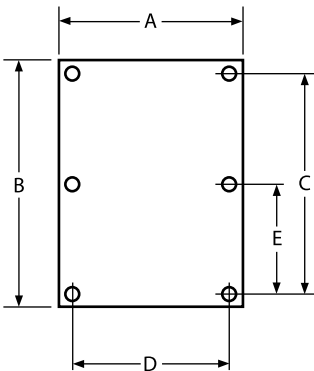

| EXB, XJB MOUNTING PAN | | | | | | | | |
|-----------------------|-------------------------|--------|------------------------|----------|------------------------|---------|---------|---------------|
| CATALOG NUMBER | NOMINAL INSIDE BOX SIZE | | MOUNTING PAN DIMENSION | | MOUNTING HOLE SPACINGS | | | PAN THICKNESS |
| | WIDTH | LENGTH | A WIDTH | B LENGTH | C | D | E | |
| 7998-4 | 5" | 10" | 4-1/2" | 9" | 6-29/32" | 3" | — | .125 |
| 7998-5 | 5" | 13" | 4-1/2" | 12" | 10" | 2" | — | .125 |
| 7997-5 | 6" | 6" | 5" | 5" | 3" | 3" | — | .125 |
| 7997-1 | 6" | 8" | 5" | 7" | 5" | 3" | — | .125 |
| 7997-6 | 6" | 12" | 5" | 11" | 9" | 3" | — | .125 |
| 7996-1 | 8" | 8" | 7" | 7" | 5" | 5" | — | .125 |
| 7996-2 | 8" | 10" | 7" | 9" | 7" | 5" | — | .125 |
| 17619 | 8" | 12" | 7" | 11" | 9" | 5" | — | .125 |
| 7996-4 | 8" | 13" | 7" | 12" | 10" | 5" | — | .125 |
| 7996-5 | 8" | 15" | 7" | 14-1/2" | 12-1/2" | 5" | — | .125 |
| 7996-6 | 8" | 18" | 7" | 17" | 15-1/8" | 5" | — | .125 |
| 17617 | 10" | 14" | 9" | 13" | 11" | 7" | — | .125 |
| 17618 | 10" | 10" | 9" | 9" | 7" | 7" | — | .125 |
| 7988-1 | 12" | 12" | 10-1/2" | 10-1/2" | 9" | 9" | — | .125 |
| 15515 | 12" | 18" | 10" | 16" | 15" | 9" | 7-1/2" | .125 |
| 7988-4 | 12" | 24" | 10-1/4" | 22-1/4" | 21" | 9" | — | .125 |
| 17620 | 12" | 36" | 11" | 35" | 33" | 9" | 17-1/2" | .125 |
| 17621 | 14" | 14" | 13" | 13" | 11" | 11" | — | .125 |
| 7995-1 | 16" | 16" | 14" | 14" | 13" | 13" | — | .125 |
| 7995-2 | 16" | 24" | 14-1/2" | 23" | 21" | 13" | — | .125 |
| 17622 | 16" | 24" | 15" | 23" | 21" | 13" | — | .125 |
| 7995-5 | 16" | 48" | 14-1/2" | 46-1/2" | 45" | 13" | 22-1/2" | .190 |
| 17623 | 18" | 18" | 17" | 17" | 15" | 15" | — | .190 |
| 15516 | 18" | 24" | 16-3/8" | 22-1/8" | 21" | 15" | 10-1/2" | .125 |
| 15517 | 18" | 36" | 34" | 16" | 33" | 15" | 16-1/2" | .125 |
| 7999-1 | 20" | 24" | 18-1/2" | 22-1/2" | 21" | 17" | — | .125 |
| 7999-2 | 20" | 32" | 18-1/2" | 30-1/2" | 29" | 17" | 14-1/2" | .190 |
| 17596 | 20" | 36" | 18-3/4" | 34-3/4" | 32-3/4" | 16-3/4" | 16-3/8" | .190 |
| 7999-3 | 20" | 40" | 18-1/2" | 39" | 37" | 17" | 18-1/2" | .190 |
| 8000-1 | 24" | 24" | 22-1/4" | 22-1/4" | 21" | 21" | — | .125 |
| 17624 | 24" | 36" | 23" | 35" | 33" | 21" | 16-1/2" | .190 |
| 205767 | 24" | 30" | 23" | 29" | 27" | 21" | 13-1/2" | .190 |
| 22061 | 18" | 30" | 16" | 29" | 28" | 15" | 14" | .125 |

DB Series Mounting Pans Ordering Instructions

Select proper mounting pan based on outside (length & width) of box. Order and price as separate item from the junction box catalog number.

EXAMPLE: DB-10106 } assemble
6248-10

DB Series boxes are provided with 1/2" raised mounting studs threaded into the back when pans are ordered. If a mounting pan is not ordered, mounting studs can still be provided by adding SU8 to box catalog number. See price list for SU8 pricing information.

| DB MOUNTING PAN | | | | | | | | |
|-----------------|-------|--------|---------|----------|---------|---------|---------|---------------|
| CATALOG NUMBER | WIDTH | LENGTH | A WIDTH | B LENGTH | C | D | E | PAN THICKNESS |
| 6307-6 | 6" | 6" | 4" | 4" | 3" | 3" | — | .125 |
| 6307-12 | 6" | 12" | 4" | 10" | 8-1/2" | 3" | — | .125 |
| 6247-8 | 8" | 8" | 5" | 5" | 3-1/4" | 3-1/4" | — | .125 |
| 6247-10 | 8" | 10" | 5" | 7" | 5-1/4" | 3-1/4" | — | .125 |
| 6247-14 | 8" | 14" | 5" | 11" | 9-1/4" | 3-1/4" | — | .125 |
| 6247-18 | 8" | 18" | 5" | 15" | 13-1/4" | 3-1/4" | — | .125 |
| 6248-10 | 10" | 10" | 7" | 7" | 5-1/4" | 5-1/4" | — | .125 |
| 6248-14 | 10" | 14" | 7" | 11" | 9-1/4" | 5-1/4" | — | .125 |
| 6249-14 | 12" | 14" | 9" | 11" | 9-1/4" | 7-1/4" | — | .125 |
| 6249-16 | 12" | 16" | 9" | 13" | 11-1/4" | 7-1/4" | — | .125 |
| 6249-18 | 12" | 18" | 9" | 15" | 13-1/4" | 7-1/4" | — | .125 |
| 6249-24 | 12" | 24" | 9" | 21" | 19-1/4" | 7-1/4" | — | .125 |
| 6250-18 | 16" | 18" | 13" | 15" | 13-1/4" | 11-1/4" | — | .125 |
| 6250-24 | 16" | 24" | 13" | 21" | 19-1/4" | 11-1/4" | — | .125 |
| 6250-36 | 16" | 36" | 13" | 33" | 31-1/4" | 11-1/4" | 15-5/8" | .125 |
| 6251-24 | 20" | 24" | 17" | 21" | 19-1/4" | 15-1/4" | — | .125 |
| 6251-30 | 20" | 30" | 17" | 27" | 25-1/4" | 15-1/4" | — | .125 |
| 6252-30 | 24" | 30" | 18-3/4" | 24-3/4" | 23" | 17" | — | .125 |
| 6252-36 | 24" | 36" | 18-3/4" | 30-3/4" | 29" | 17" | 14-1/2" | .190 |