

EXB, XB and XJB Series Mounting Pans Ordering Instructions

Select proper mounting pan based on inside (length & width) of box. Order and price as separate item from junction box catalog number.

EXAMPLE: XB-12128 } assemble
7988-1


EXB, XB and XJB Series boxes have cast bosses which are drilled and tapped for direct mounting when pans are ordered.

Mounting pans are 1/8" thick sheet aluminum and are sized to provide the maximum usable surface area when installed.

Mounting pans are installed at no additional charge when ordered with box.

All EXB-XB-XJB series boxes have internal bosses that are factory machined to accept mounting pans.

Dimensions

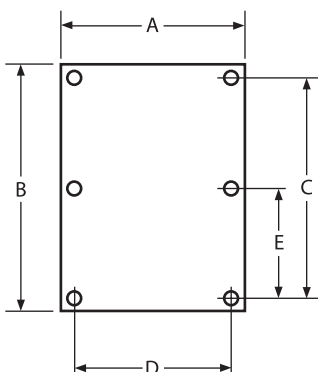

CATALOG NUMBER	NOMINAL INSIDE BOX SIZE		MOUNTING PAN DIMENSION		MOUNTING HOLE SPACINGS			PAN THICKNESS
	WIDTH	LENGTH	A WIDTH	B LENGTH	C	D	E	
9547-1	4"	4"	3"	3"	2"	2"	—	.125
9547-2	4"	6"	3"	5"	4"	2"	—	.125
7998-4	5"	10"	4-1/2"	9"	6-29/32"	3"	—	.125
7998-5	5"	13"	4-1/2"	12"	10"	2"	—	.125
7997-5	6"	6"	5"	5"	3"	3"	—	.125
7997-1	6"	8"	5"	7"	5"	3"	—	.125
7997-6	6"	12"	5"	11"	9"	3"	—	.125
7996-1	8"	8"	7"	7"	5"	5"	—	.125
7996-2	8"	10"	7"	9"	7"	5"	—	.125
17619	8"	12"	7"	11"	9"	5"	—	.125
7996-4	8"	13"	7"	12"	10"	5"	—	.125
7996-5	8"	15"	7"	14-1/2"	12-1/2"	5"	—	.125
7996-6	8"	18"	7"	17"	15-1/8"	5"	—	.125
7994-1	10"	12"	9"	11"	9"	7"	—	.125
17618	10"	10"	9"	9"	7"	7"	—	.125
7988-1	12"	12"	10-1/2"	10-1/2"	9"	9"	—	.125
7988-2	12"	16"	10-1/2"	14-1/2"	13"	9"	—	.125
15515	12"	18"	10"	16"	15"	9"	7-1/2"	.125
7988-3	12"	19"	10-1/2"	17-1/2"	16"	9"	—	.125
7988-4	12"	24"	10-1/4"	22-1/4"	21"	9"	—	.125
7988-5	12"	32"	10-1/2"	30-1/2"	29"	9"	14-1/2"	.125
7988-7	12"	36"	10-1/2"	34-1/2"	33"	9"	16-1/2"	.125
17621	14"	14"	13"	13"	11"	11"	—	.125
7995-1	16"	16"	14"	14"	13"	13"	—	.125
7995-2	16"	24"	14-1/2"	23"	21"	13"	—	.125
17622	16"	24"	15"	23"	21"	13"	—	.125
7995-5	16"	48"	14-1/2"	46-1/2"	45"	13"	22-1/2"	.190
17623	18"	18"	17"	17"	15"	15"	—	.190
15516	18"	24"	16-3/8"	22-1/8"	21"	15"	10-1/2"	.125
15517	18"	36"	34"	16"	33"	15"	16-1/2"	.125
7999-1	20"	24"	18-1/2"	22-1/2"	21"	17"	—	.125
7999-2	20"	32"	18-1/2"	30-1/2"	29"	17"	14-1/2"	.190
17596	20"	36"	18-3/4"	34-3/4"	32-3/4"	16-3/4"	16-3/8"	.190
7999-3	20"	40"	18-1/2"	39"	37"	17"	18-1/2"	.190
8000-1	24"	24"	22-1/4"	22-1/4"	21"	21"	—	.125
17624	24"	36"	23"	35"	33"	21"	16-1/2"	.190
205767	24"	30"	23"	29"	27"	21"	13-1/2"	.190

DB Series Mounting Pans Ordering Instructions

Select proper mounting pan based on outside (length & width) of box. Order and price as separate item from the junction box catalog number.

EXAMPLE: DB-10106 } assemble
6248-10

DB Series boxes are provided with 1/2" raised mounting studs threaded into the back when pans are ordered. If a mounting pan is not ordered, mounting studs can still be provided by adding SU8 to box catalog number. See price list for SU8 pricing information.

DB MOUNTING PAN								
6307-6	6"	6"	4"	4"	3"	3"	—	.125
6307-12	6"	12"	4"	10"	8-1/2"	3"	—	.125
6247-8	8"	8"	5"	5"	3-1/4"	3-1/4"	—	.125
6247-10	8"	10"	5"	7"	5-1/4"	3-1/4"	—	.125
6247-14	8"	14"	5"	11"	9-1/4"	3-1/4"	—	.125
6247-18	8"	18"	5"	15"	13-1/4"	3-1/4"	—	.125
6248-10	10"	10"	7"	7"	5-1/4"	5-1/4"	—	.125
6248-14	10"	14"	7"	11"	9-1/4"	5-1/4"	—	.125
6249-14	12"	14"	9"	11"	9-1/4"	7-1/4"	—	.125
6249-16	12"	16"	9"	13"	11-1/4"	7-1/4"	—	.125
6249-18	12"	18"	9"	15"	13-1/4"	7-1/4"	—	.125
6249-24	12"	24"	9"	21"	19-1/4"	7-1/4"	—	.125
6250-18	16"	18"	13"	15"	13-1/4"	11-1/4"	—	.125
6250-24	16"	24"	13"	21"	19-1/4"	11-1/4"	—	.125
6250-36	16"	36"	13"	33"	31-1/4"	11-1/4"	15-5/8"	.125
6251-24	20"	24"	17"	21"	19-1/4"	15-1/4"	—	.125
6251-30	20"	30"	17"	27"	25-1/4"	15-1/4"	—	.125
6252-30	24"	30"	18-3/4"	24-3/4"	23"	17"	—	.125
6252-36	24"	36"	18-3/4"	30-3/4"	29"	17"	14-1/2"	.190

