

LIGHTING

CERTILITE® V SERIES



HIGH PRESSURE SODIUM, 50-150W MOGUL BASE HID



Pendant
w/ 5-1/2"
Globe & Guard



Flexible Pendant
w/ 5-1/2"
Refractor & Guard



Pendant
w/ 7-3/4"
Globe & Guard



Flexible Pendant
w/ 7-3/4"
Refractor & Guard



Pendant
w/ Enclosed Reflector

Class I, Div. 2, Groups A,B,C,D^①
Class I, Zone 2, Groups IIC, IIB, IIA
Class II, Div. 1 & 2, Groups E,F,G
Class III
Suitable for wet locations
NEMA 3, 4, 4X
IP66

UL US LISTED - File E10514 (Hazardous & Marine)

CSB US Certified - File LR11713

NR Restricted Breathing Option^⑤

Class I, Zone 2 AEx nAnR

Class I, Zone 2 Ex nR



VM 50 - 150 WATT HIGH PRESSURE SODIUM PENDANT

DESCRIPTION				5-1/2" OPTIC THREAD SIZE ^②			7-3/4" OPTIC THREAD SIZE ^②			
WATTS	ANSI	HUB SIZE ^③	VOLTAGE ^④	GLOBE & GUARD	TYPE I GLASS REFRACTOR & GUARD	TYPE V GLASS REFRACTOR & GUARD	GLOBE & GUARD	TYPE I GLASS REFRACTOR & GUARD	TYPE V GLASS REFRACTOR & GUARD	12" SPIN-TOP TYPE V REFRACTOR & GUARD
50	S68	3/4"	Quad	VM3S050A2GLG	VM3S050A2R1G	VM3S050A2R5G	VM4S050A2GLG	VM4S050A2R1G	VM4S050A2R5G	VM4S050A2ERN
70	S62	3/4"	Quad Tri 480	VM3S070A2GLG	VM3S070A2R1G	VM3S070A2R5G	VM4S070A2GLG	VM4S070A2R1G	VM4S070A2R5G	VM4S070A2ERN
				VM3S076A2GLG	VM3S076A2R1G	VM3S076A2R5G	VM4S076A2GLG	VM4S076A2R1G	VM4S076A2R5G	VM4S076A2ERN
				VM3S075A2GLG	VM3S075A2R1G	VM3S075A2R5G	VM4S075A2GLG	VM4S075A2R1G	VM4S075A2R5G	VM4S075A2ERN
100	S54	3/4"	Quad Tri 480	VM3S100A2GLG	VM3S100A2R1G	VM3S100A2R5G	VM4S100A2GLG	VM4S100A2R1G	VM4S100A2R5G	VM4S100A2ERN
				VM3S106A2GLG	VM3S106A2R1G	VM3S106A2R5G	VM4S106A2GLG	VM4S106A2R1G	VM4S106A2R5G	VM4S106A2ERN
				VM3S105A2GLG	VM3S105A2R1G	VM3S105A2R5G	VM4S105A2GLG	VM4S105A2R1G	VM4S105A2R5G	VM4S105A2ERN
150	S55	3/4"	Quad Tri 480	VM3S150A2GLG	VM3S150A2R1G	VM3S150A2R5G	VM4S150A2GLG	VM4S150A2R1G	VM4S150A2R5G	VM4S150A2ERN
				VM3S156A2GLG	VM3S156A2R1G	VM3S156A2R5G	VM4S156A2GLG	VM4S156A2R1G	VM4S156A2R5G	VM4S156A2ERN
				VM3S155A2GLG	VM3S155A2R1G	VM3S155A2R5G	VM4S155A2GLG	VM4S155A2R1G	VM4S155A2R5G	VM4S155A2ERN

VM 50 - 150 WATT HIGH PRESSURE SODIUM FLEXIBLE PENDANT

DESCRIPTION				5-1/2" OPTIC THREAD SIZE ^②			7-3/4" OPTIC THREAD SIZE ^②			
WATTS	ANSI	HUB SIZE ^③	VOLTAGE ^④	GLOBE & GUARD	TYPE I GLASS REFRACTOR & GUARD	TYPE V GLASS REFRACTOR & GUARD	GLOBE & GUARD	TYPE I GLASS REFRACTOR & GUARD	TYPE V GLASS REFRACTOR & GUARD	12" SPIN-TOP TYPE V REFRACTOR & GUARD
50	S68	3/4"	Quad	VM3S050F2GLG	VM3S050F2R1G	VM3S050F2R5G	VM4S050F2GLG	VM4S050F2R1G	VM4S050F2R5G	VM4S050F2ERN
70	S62	3/4"	Quad Tri 480	VM3S070F2GLG	VM3S070F2R1G	VM3S070F2R5G	VM4S070F2GLG	VM4S070F2R1G	VM4S070F2R5G	VM4S070F2ERN
				VM3S076F2GLG	VM3S076F2R1G	VM3S076F2R5G	VM4S076F2GLG	VM4S076F2R1G	VM4S076F2R5G	VM4S076F2ERN
				VM3S075F2GLG	VM3S075F2R1G	VM3S075F2R5G	VM4S075F2GLG	VM4S075F2R1G	VM4S075F2R5G	VM4S075F2ERN
100	S54	3/4"	Quad Tri 480	VM3S100F2GLG	VM3S100F2R1G	VM3S100F2R5G	VM4S100F2GLG	VM4S100F2R1G	VM4S100F2R5G	VM4S100F2ERN
				VM3S106F2GLG	VM3S106F2R1G	VM3S106F2R5G	VM4S106F2GLG	VM4S106F2R1G	VM4S106F2R5G	VM4S106F2ERN
				VM3S105F2GLG	VM3S105F2R1G	VM3S105F2R5G	VM4S105F2GLG	VM4S105F2R1G	VM4S105F2R5G	VM4S105F2ERN
150	S55	3/4"	Quad Tri 480	VM3S150F2GLG	VM3S150F2R1G	VM3S150F2R5G	VM4S150F2GLG	VM4S150F2R1G	VM4S150F2R5G	VM4S150F2ERN
				VM3S156F2GLG	VM3S156F2R1G	VM3S156F2R5G	VM4S156F2GLG	VM4S156F2R1G	VM4S156F2R5G	VM4S156F2ERN
				VM3S155F2GLG	VM3S155F2R1G	VM3S155F2R5G	VM4S155F2GLG	VM4S155F2R1G	VM4S155F2R5G	VM4S155F2ERN

① See hazardous application data on pages L131 - L140 for limitations.

② Catalog numbers shown are with guard (except enclosed reflector); to omit guard change ending G to N; e.g. VM3S050A2GLN

③ Catalog numbers shown are with 3/4" conduit openings; change 2 to 3 for 1"; e.g. VM3S050A3GLG.

④ Consult catalog logic for other available voltages.

⑤ Add suffix NR for restricted breathing; see page L84 for more information.



HIGH PRESSURE SODIUM, 50-150W MOGUL BASE HID



Ceiling
w/ 5-1/2"
Globe & Guard



Wall
w/ 5-1/2"
Refractor & Guard



Ceiling
w/ 7-3/4"
Globe & Guard



Wall
w/ 7-3/4"
Refractor & Guard



Ceiling
w/ Enclosed Reflector

VM 50 - 150 WATT HIGH PRESSURE SODIUM CEILING

DESCRIPTION				5-1/2" OPTIC THREAD SIZE ②			7-3/4" OPTIC THREAD SIZE ②			
WATTS	ANSI	HUB SIZE ③	VOLTAGE ④	GLOBE & GUARD	TYPE I GLASS REFRACTOR & GUARD	TYPE V GLASS REFRACTOR & GUARD	GLOBE & GUARD	TYPE I GLASS REFRACTOR & GUARD	TYPE V GLASS REFRACTOR & GUARD	12" SPIN-TOP TYPE V REFRACTOR & GUARD
50	S68	3/4"	Quad	VM3S050X2GLG	VM3S050X2R1G	VM3S050X2R5G	VM4S050X2GLG	VM4S050X2R1G	VM4S050X2R5G	VM4S050X2ERN
70	S62	3/4"	Quad Tri 480	VM3S070X2GLG	VM3S070X2R1G	VM3S070X2R5G	VM4S070X2GLG	VM4S070X2R1G	VM4S070X2R5G	VM4S070X2ERN
				VM3S076X2GLG	VM3S076X2R1G	VM3S076X2R5G	VM4S076X2GLG	VM4S076X2R1G	VM4S076X2R5G	VM4S076X2ERN
				VM3S075X2GLG	VM3S075X2R1G	VM3S075X2R5G	VM4S075X2GLG	VM4S075X2R1G	VM4S075X2R5G	VM4S075X2ERN
100	S54	3/4"	Quad Tri 480	VM3S100X2GLG	VM3S100X2R1G	VM3S100X2R5G	VM4S100X2GLG	VM4S100X2R1G	VM4S100X2R5G	VM4S100X2ERN
				VM3S106X2GLG	VM3S106X2R1G	VM3S106X2R5G	VM4S106X2GLG	VM4S106X2R1G	VM4S106X2R5G	VM4S106X2ERN
				VM3S105X2GLG	VM3S105X2R1G	VM3S105X2R5G	VM4S105X2GLG	VM4S105X2R1G	VM4S105X2R5G	VM4S105X2ERN
150	S55	3/4"	Quad Tri 480	VM3S150X2GLG	VM3S150X2R1G	VM3S150X2R5G	VM4S150X2GLG	VM4S150X2R1G	VM4S150X2R5G	VM4S150X2ERN
				VM3S156X2GLG	VM3S156X2R1G	VM3S156X2R5G	VM4S156X2GLG	VM4S156X2R1G	VM4S156X2R5G	VM4S156X2ERN
				VM3S155X2GLG	VM3S155X2R1G	VM3S155X2R5G	VM4S155X2GLG	VM4S155X2R1G	VM4S155X2R5G	VM4S155X2ERN

VM 50 - 150 WATT HIGH PRESSURE SODIUM FLEXIBLE PENDANT

DESCRIPTION				5-1/2" OPTIC THREAD SIZE ②			7-3/4" OPTIC THREAD SIZE ②			
WATTS	ANSI	HUB SIZE ③	VOLTAGE ④	GLOBE & GUARD	TYPE I GLASS REFRACTOR & GUARD	TYPE V GLASS REFRACTOR & GUARD	GLOBE & GUARD	TYPE I GLASS REFRACTOR & GUARD	TYPE V GLASS REFRACTOR & GUARD	12" SPIN-TOP TYPE V REFRACTOR & GUARD
50	S68	3/4"	Quad	VM3S050F2GLG	VM3S050F2R1G	VM3S050F2R5G	VM4S050F2GLG	VM4S050F2R1G	VM4S050F2R5G	VM4S050F2ERN
70	S62	3/4"	Quad Tri 480	VM3S070F2GLG	VM3S070F2R1G	VM3S070F2R5G	VM4S070F2GLG	VM4S070F2R1G	VM4S070F2R5G	VM4S070F2ERN
				VM3S076F2GLG	VM3S076F2R1G	VM3S076F2R5G	VM4S076F2GLG	VM4S076F2R1G	VM4S076F2R5G	VM4S076F2ERN
				VM3S075F2GLG	VM3S075F2R1G	VM3S075F2R5G	VM4S075F2GLG	VM4S075F2R1G	VM4S075F2R5G	VM4S075F2ERN
100	S54	3/4"	Quad Tri 480	VM3S100F2GLG	VM3S100F2R1G	VM3S100F2R5G	VM4S100F2GLG	VM4S100F2R1G	VM4S100F2R5G	VM4S100F2ERN
				VM3S106F2GLG	VM3S106F2R1G	VM3S106F2R5G	VM4S106F2GLG	VM4S106F2R1G	VM4S106F2R5G	VM4S106F2ERN
				VM3S105F2GLG	VM3S105F2R1G	VM3S105F2R5G	VM4S105F2GLG	VM4S105F2R1G	VM4S105F2R5G	VM4S105F2ERN
150	S55	3/4"	Quad Tri 480	VM3S150F2GLG	VM3S150F2R1G	VM3S150F2R5G	VM4S150F2GLG	VM4S150F2R1G	VM4S150F2R5G	VM4S150F2ERN
				VM3S156F2GLG	VM3S156F2R1G	VM3S156F2R5G	VM4S156F2GLG	VM4S156F2R1G	VM4S156F2R5G	VM4S156F2ERN
				VM3S155F2GLG	VM3S155F2R1G	VM3S155F2R5G	VM4S155F2GLG	VM4S155F2R1G	VM4S155F2R5G	VM4S155F2ERN

① See hazardous application data on pages L131 - L140 for limitations.

② Catalog numbers shown are with guard (except enclosed reflector); to omit guard change ending G to N; e.g. VM3S050A2GLN

③ Catalog numbers shown are with 3/4" conduit openings; change 2 to 3 for 1"; e.g. VM3S050A3GLG.

④ Consult catalog logic for other available voltages.


⑤ Add suffix NR for restricted breathing; see page L84 for more information.



LIGHTING

CERTILITE® V SERIES

HIGH PRESSURE SODIUM, 50-150W MOGUL BASE HID

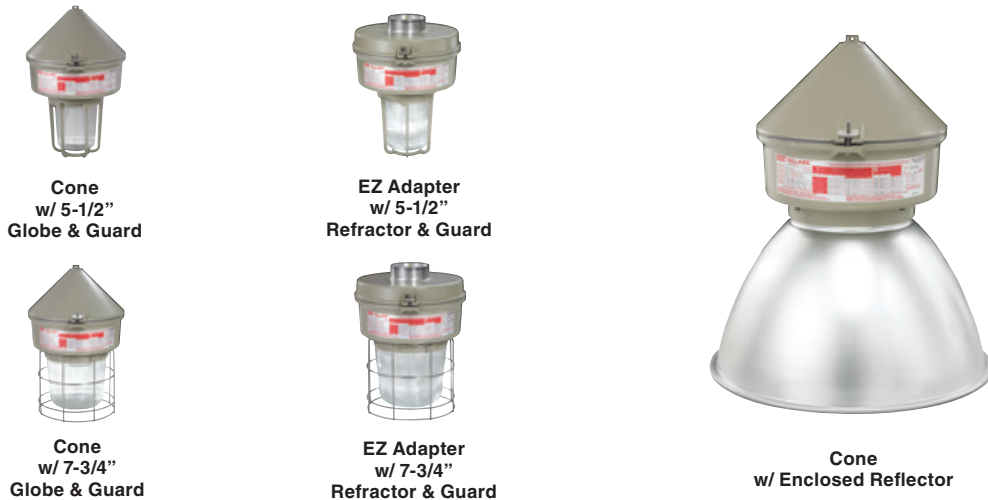

VM 50 - 150 WATT HIGH PRESSURE SODIUM CONE										
DESCRIPTION				5-1/2" OPTIC THREAD SIZE ②			7-3/4" OPTIC THREAD SIZE ②			
WATTS	ANSI	HUB SIZE ③	VOLTAGE ④	GLOBE & GUARD	TYPE I GLASS REFRACTOR & GUARD	TYPE V GLASS REFRACTOR & GUARD	GLOBE & GUARD	TYPE I GLASS REFRACTOR & GUARD	TYPE V GLASS REFRACTOR & GUARD	12" SPIN-TOP TYPE V REFRACTOR & GUARD
50	S68	3/4"	Quad	VM3S050C2GLG	VM3S050C2R1G	VM3S050C2R5G	VM4S050C2GLG	VM4S050C2R1G	VM4S050C2R5G	VM4S050C2ERN
				VM3S070C2GLG	VM3S070C2R1G	VM3S070C2R5G	VM4S070C2GLG	VM4S070C2R1G	VM4S070C2R5G	VM4S070C2ERN
70	S62	3/4"	Quad Tri 480	VM3S076C2GLG	VM3S076C2R1G	VM3S076C2R5G	VM4S076C2GLG	VM4S076C2R1G	VM4S076C2R5G	VM4S076C2ERN
				VM3S075C2GLG	VM3S075C2R1G	VM3S075C2R5G	VM4S075C2GLG	VM4S075C2R1G	VM4S075C2R5G	VM4S075C2ERN
				VM3S100C2GLG	VM3S100C2R1G	VM3S100C2R5G	VM4S100C2GLG	VM4S100C2R1G	VM4S100C2R5G	VM4S100C2ERN
100	S54	3/4"	Quad Tri 480	VM3S106C2GLG	VM3S106C2R1G	VM3S106C2R5G	VM4S106C2GLG	VM4S106C2R1G	VM4S106C2R5G	VM4S106C2ERN
				VM3S105C2GLG	VM3S105C2R1G	VM3S105C2R5G	VM4S105C2GLG	VM4S105C2R1G	VM4S105C2R5G	VM4S105C2ERN
				VM3S150C2GLG	VM3S150C2R1G	VM3S150C2R5G	VM4S150C2GLG	VM4S150C2R1G	VM4S150C2R5G	VM4S150C2ERN
150	S55	3/4"	Quad Tri 480	VM3S156C2GLG	VM3S156C2R1G	VM3S156C2R5G	VM4S156C2GLG	VM4S156C2R1G	VM4S156C2R5G	VM4S156C2ERN
				VM3S155C2GLG	VM3S155C2R1G	VM3S155C2R5G	VM4S155C2GLG	VM4S155C2R1G	VM4S155C2R5G	VM4S155C2ERN

VM 50 - 150 WATT HIGH PRESSURE SODIUM EZ ADAPTER ⑥										
DESCRIPTION				5-1/2" OPTIC THREAD SIZE ②			7-3/4" OPTIC THREAD SIZE ②			
WATTS	ANSI	HUB SIZE ③	VOLTAGE ④	GLOBE & GUARD	TYPE I GLASS REFRACTOR & GUARD	TYPE V GLASS REFRACTOR & GUARD	GLOBE & GUARD	TYPE I GLASS REFRACTOR & GUARD	TYPE V GLASS REFRACTOR & GUARD	12" SPIN-TOP TYPE V REFRACTOR & GUARD
50	S68	Ⓞ	Quad	VM3S050EZGLG	VM3S050EZR1G	VM3S050EZR5G	VM4S050EZGLG	VM4S050EZR1G	VM4S050EZR5G	VM4S050EZERN
				VM3S070EZGLG	VM3S070EZR1G	VM3S070EZR5G	VM4S070EZGLG	VM4S070EZR1G	VM4S070EZR5G	VM4S070EZERN
70	S62	Ⓞ	Quad Tri 480	VM3S076EZGLG	VM3S076EZR1G	VM3S076EZR5G	VM4S076EZGLG	VM4S076EZR1G	VM4S076EZR5G	VM4S076EZERN
				VM3S075EZGLG	VM3S075EZR1G	VM3S075EZR5G	VM4S075EZGLG	VM4S075EZR1G	VM4S075EZR5G	VM4S075EZERN
				VM3S100EZGLG	VM3S100EZR1G	VM3S100EZR5G	VM4S100EZGLG	VM4S100EZR1G	VM4S100EZR5G	VM4S100EZERN
100	S54	Ⓞ	Quad Tri 480	VM3S106EZGLG	VM3S106EZR1G	VM3S106EZR5G	VM4S106EZGLG	VM4S106EZR1G	VM4S106EZR5G	VM4S106EZERN
				VM3S105EZGLG	VM3S105EZR1G	VM3S105EZR5G	VM4S105EZGLG	VM4S105EZR1G	VM4S105EZR5G	VM4S105EZERN
				VM3S150EZGLG	VM3S150EZR1G	VM3S150EZR5G	VM4S150EZGLG	VM4S150EZR1G	VM4S150EZR5G	VM4S150EZERN
150	S55	Ⓞ	Quad Tri 480	VM3S156EZGLG	VM3S156EZR1G	VM3S156EZR5G	VM4S156EZGLG	VM4S156EZR1G	VM4S156EZR5G	VM4S156EZERN
				VM3S155EZGLG	VM3S155EZR1G	VM3S155EZR5G	VM4S155EZGLG	VM4S155EZR1G	VM4S155EZR5G	VM4S155EZERN

① See hazardous application data on pages L131 - L140 for limitations.
 ② Catalog numbers shown are with guard (except enclosed reflector); to omit guard change ending G to N; e.g. VM3S050C2GLN
 ③ Cone top catalog numbers shown are with 3/4" conduit openings, change 2 to 3 for 1"; e.g. VM3S050C3GLG.
 ④ Consult catalog logic for other available voltages.
 ⑤ Add suffix NR for restricted breathing; see page L84 for more information.
 ⑥ VMEZA tank adapters UL "classified" as an assembly for use between VM tanks and EZ mounts. Order EZ mounts separately.



HIGH PRESSURE SODIUM, 50-150W MOGUL BASE HID



Stanchion 25°
w/ 5-1/2"
Globe & Guard



Stanchion Straight
w/ 5-1/2"
Reflector & Guard



Stanchion 25°
w/ 7-3/4"
Globe & Guard



Stanchion Straight
w/ 7-3/4"
Reflector & Guard



Stanchion 25°
w/ Enclosed Reflector

VM 50 - 150 WATT HIGH PRESSURE SODIUM STANCHION 25° ANGLE

DESCRIPTION				5-1/2" OPTIC THREAD SIZE ②			7-3/4" OPTIC THREAD SIZE ②			
WATTS	ANSI	HUB SIZE ③	VOLTAGE ④	GLOBE & GUARD	TYPE I GLASS REFRACTOR & GUARD	TYPE V GLASS REFRACTOR & GUARD	GLOBE & GUARD	TYPE I GLASS REFRACTOR & GUARD	TYPE V GLASS REFRACTOR & GUARD	ENCLOSED REFLECTOR
50	S68	1-1/2"	Quad	VM3S050D5GLG	VM3S050D5R1G	VM3S050D5R5G	VM4S050D5GLG	VM4S050D5R1G	VM4S050D5R5G	VM4S050D5ERN
70	S62	1-1/2"	Quad Tri 480	VM3S070D5GLG	VM3S070D5R1G	VM3S070D5R5G	VM4S070D5GLG	VM4S070D5R1G	VM4S070D5R5G	VM4S070D5ERN
				VM3S076D5GLG	VM3S076D5R1G	VM3S076D5R5G	VM4S076D5GLG	VM4S076D5R1G	VM4S076D5R5G	VM4S076D5ERN
				VM3S075D5GLG	VM3S075D5R1G	VM3S075D5R5G	VM4S075D5GLG	VM4S075D5R1G	VM4S075D5R5G	VM4S075D5ERN
100	S54	1-1/2"	Quad Tri 480	VM3S100D5GLG	VM3S100D5R1G	VM3S100D5R5G	VM4S100D5GLG	VM4S100D5R1G	VM4S100D5R5G	VM4S100D5ERN
				VM3S106D5GLG	VM3S106D5R1G	VM3S106D5R5G	VM4S106D5GLG	VM4S106D5R1G	VM4S106D5R5G	VM4S106D5ERN
				VM3S105D5GLG	VM3S105D5R1G	VM3S105D5R5G	VM4S105D5GLG	VM4S105D5R1G	VM4S105D5R5G	VM4S105D5ERN
150	S55	1-1/2"	Quad Tri 480	VM3S150D5GLG	VM3S150D5R1G	VM3S150D5R5G	VM4S150D5GLG	VM4S150D5R1G	VM4S150D5R5G	VM4S150D5ERN
				VM3S156D5GLG	VM3S156D5R1G	VM3S156D5R5G	VM4S156D5GLG	VM4S156D5R1G	VM4S156D5R5G	VM4S156D5ERN
				VM3S155D5GLG	VM3S155D5R1G	VM3S155D5R5G	VM4S155D5GLG	VM4S155D5R1G	VM4S155D5R5G	VM4S155D5ERN

VM 50 - 150 WATT HIGH PRESSURE SODIUM STANCHION STRAIGHT

DESCRIPTION				5-1/2" OPTIC THREAD SIZE ②			7-3/4" OPTIC THREAD SIZE ②			
WATTS	ANSI	HUB SIZE ③	VOLTAGE ④	GLOBE & GUARD	TYPE I GLASS REFRACTOR & GUARD	TYPE V GLASS REFRACTOR & GUARD	GLOBE & GUARD	TYPE I GLASS REFRACTOR & GUARD	TYPE V GLASS REFRACTOR & GUARD	ENCLOSED REFLECTOR
50	S68	1-1/2"	Quad	VM3S050S5GLG	VM3S050S5R1G	VM3S050S5R5G	VM4S050S5GLG	VM4S050S5R1G	VM4S050S5R5G	VM4S050S5ERN
70	S62	1-1/2"	Quad Tri 480	VM3S070S5GLG	VM3S070S5R1G	VM3S070S5R5G	VM4S070S5GLG	VM4S070S5R1G	VM4S070S5R5G	VM4S070S5ERN
				VM3S076S5GLG	VM3S076S5R1G	VM3S076S5R5G	VM4S076S5GLG	VM4S076S5R1G	VM4S076S5R5G	VM4S076S5ERN
				VM3S075S5GLG	VM3S075S5R1G	VM3S075S5R5G	VM4S075S5GLG	VM4S075S5R1G	VM4S075S5R5G	VM4S075S5ERN
100	S54	1-1/2"	Quad Tri 480	VM3S100S5GLG	VM3S100S5R1G	VM3S100S5R5G	VM4S100S5GLG	VM4S100S5R1G	VM4S100S5R5G	VM4S100S5ERN
				VM3S106S5GLG	VM3S106S5R1G	VM3S106S5R5G	VM4S106S5GLG	VM4S106S5R1G	VM4S106S5R5G	VM4S106S5ERN
				VM3S105S5GLG	VM3S105S5R1G	VM3S105S5R5G	VM4S105S5GLG	VM4S105S5R1G	VM4S105S5R5G	VM4S105S5ERN
150	S55	1-1/2"	Quad Tri 480	VM3S150S5GLG	VM3S150S5R1G	VM3S150S5R5G	VM4S150S5GLG	VM4S150S5R1G	VM4S150S5R5G	VM4S150S5ERN
				VM3S156S5GLG	VM3S156S5R1G	VM3S156S5R5G	VM4S156S5GLG	VM4S156S5R1G	VM4S156S5R5G	VM4S156S5ERN
				VM3S155S5GLG	VM3S155S5R1G	VM3S155S5R5G	VM4S155S5GLG	VM4S155S5R1G	VM4S155S5R5G	VM4S155S5ERN

① See hazardous application data on pages L131 - L140 for limitations.

② Catalog numbers shown are with guard (except enclosed reflector); to omit guard change ending G to N; e.g. VM3S050D5GLN

③ Catalog numbers shown are with 1-1/2" conduit openings, change 5 to 4 for 1-1/4"; e.g. VM3S050D4GLG.

④ Consult catalog logic for other available voltages.

⑤ Add suffix NR for restricted breathing; see page L84 for more information.