


ACCEPTOR[®] Quick Wire Series Connectors



CROSS REFERENCE BY MANUFACTURER - page 1

CROSS REFERENCE TABLE VERBIAGE			
KILLARK PART NUMBER	KILLARK OLD P/N	APPLETON	CROUSE HINDS
PLUGS			
UGP-15231QW	UGP-15231	ECP-1523	ENP5151
UGP-15232QW	UGP-15232	—	ENP6152
UGP-20231QW	UGP-20231	ECP-2023	ENP5201
UGP-20232QW	UGP-20232	ECP-20232	ENP6202
RECEPTACLE COVER			
UGR0-20231QW	UGR0-20231	EFSR-2023	ENR5201
UGR0C-15231QW	UGR0C-15231	—	ENR5151
UGR0-20232QW	UGR0-20232	EFSR-20232	ENR6202
UGR0C-15232QW	UGR0C-15232	—	ENR6152
SINGLE GANG RECEPTACLES			
UGR1-20231QW	UGR1-20231	EFS150-2023	ENR11201
UGR2-20231QW	UGR2-20231	EFS175-2023	ENR21201
UGR3-20231QW	UGR3-20231	EFS110-2023	ENR31201
UGR4-20231QW	UGR4-20231	EFSC150-2023	ENRC11201
UGR5-20231QW	UGR5-20231	EFSC175-2023	ENRC21201
UGR6-20231QW	UGR6-20231	EFSC110-2023	ENRC31201
UGR1C-15231QW	UGR1C-15231	—	ENR11151
UGR2C-15231QW	UGR2C-15231	—	ENR21151
UGR3C-15231QW	UGR3C-15231	—	ENR31151
UGR4C-15231QW	UGR4C-15231	—	ENRC11151
UGR5C-15231QW	UGR5C-15231	—	ENRC21151
UGR6C-15231QW	UGR6C-15231	—	ENRC31151
UGR1-20232QW	UGR1-20232	EFS150-20232	ENR11202
UGR2-20232QW	UGR2-20232	EFS175-20232	ENR21202
UGR3-20232QW	UGR3-20232	EFS110-20232	ENR31202
UGR4-20232QW	UGR4-20232	EFSC150-20232	ENRC11202
UGR5-20232QW	UGR5-20232	EFSC175-20232	ENRC21202
UGR6-20232QW	UGR6-20232	EFSC110-20232	ENRC31202
UGR1C-15232QW	UGR1C-15232	—	ENR11152
UGR2C-15232QW	UGR2C-15232	—	ENR21152
UGR3C-15232QW	UGR3C-15232	—	ENR31152
UGR4C-15232QW	UGR4C-15232	—	ENRC11152
UGR5C-15232QW	UGR5C-15232	—	ENRC21152
UGR6C-15232QW	UGR6C-15232	—	ENRC31152

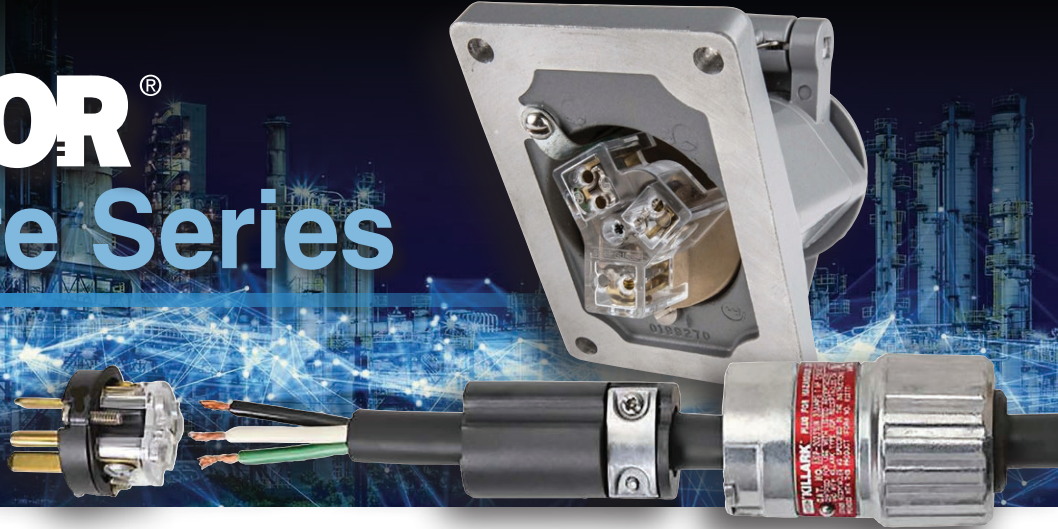

Are You Following Us?



AcceptorQW_Cross Reference 03-20 © Killark, 2020

KILLARK[®]

www.hubbell-killark.com



Harsh & Hazardous

ACCEPTOR[®] Quick Wire Series Connectors



CROSS REFERENCE BY MANUFACTURER - page 2

CROSS REFERENCE TABLE VERBIAGE			
KILLARK PART NUMBER	KILLARK OLD P/N	APPLETON	CROUSE HINDS
DOUBLE GANG RECEPTACLES			
UGR7-20231QW	UGR7-20231	EFS250-2023	ENR12201
UGR8-20231QW	UGR8-20231	EFS275-2023	ENR22201
UGR9-20231QW	UGR9-20231	EFS210-2023	ENR32201
UGR10-20231QW	UGR10-20231	EFSC250-2023	ENRC12201
UGR11-20231QW	UGR11-20231	EFSC275-2023	ENRC22201
UGR12-20231QW	UGR12-20231	EFSC210-2023	ENRC32201
UGR7C-15231QW	UGR7C-15231	—	ENR12151
UGR8C-15231QW	UGR8C-15231	—	ENR22151
UGR9C-15231QW	UGR9C-15231	—	ENR32151
UGR10C-15231QW	UGR10C-15231	—	ENRC12151
UGR11C-15231QW	UGR11C-15231	—	ENRC22151
UGR12C-15231QW	UGR12C-15231	—	ENRC32151
UGR7-20232QW	UGR7-20232	EFS250-20232	ENR12202
UGR8-20232QW	UGR8-20232	EFS275-20232	ENR22202
UGR9-20232QW	UGR9-20232	EFS210-20232	ENR32202
UGR10-20232QW	UGR10-20232	EFSC250-20232	ENRC12202
UGR11-20232QW	UGR11-20232	EFSC275-20232	ENRC22202
UGR12-20232QW	UGR12-20232	EFSC210-20232	ENRC32202
UGR7C-15232QW	UGR7C-15232	—	ENR12152
UGR8C-15232QW	UGR8C-15232	—	ENR22152
UGR9C-15232QW	UGR9C-15232	—	ENR32152
UGR10C-15232QW	UGR10C-15232	—	ENRC12152
UGR11C-15232QW	UGR11C-15232	—	ENRC22152
UGR12C-15232QW	UGR12C-15232	—	ENRC32152
PANEL MOUNT RECEPTACLE			
UGRP-20231BQW	UGRP-20231B	ECHT2023	—
UGRP-20231FQW	UGRP-20231F	ECHT2023	—
UGRP-20232BQW	UGRP-20232B	ECHT20232	—
UGRP-20232FQW	UGRP-20232F	ECHT20232	—
IN-LINE CONNECTOR RECEPTACLE			
UGRC-20231BQW	UGRC-20231B	ECCL2023/ECC2023	ENC5201 CAN
UGRC-20231FQW	UGRC-20231F	ECCL2023/ECC2023	—
UGRC-20232BQW	UGRC-20232	ECCL20232/ECC2023	ENC6202 CAN
UGRC-20232FQW	UGRC-20232F	ECCL20232/ECC2023	—



Are You Following Us?



AcceptorQW_Cross Reference 03-20 © Killark, 2020

KILLARK[®]

www.hubbell-killark.com



Harsh & Hazardous