

RIGID • IMC

Pull Elbows for Rigid Conduit • IMC



Applications

Female to Female: For connecting rigid conduit or IMC to rigid conduit or IMC to form 90° bend

Male to Female: For connecting rigid conduit or IMC to box or enclosures to form 90° bend

Features

- Raintight
- Furnished with neoprene gasketed steel cover
- Furnished with steel locknut
- Threaded for Rigid conduit and IMC (Female-NPT, Male-NPSM)

Standard Finish

Zinc plated

Standard Materials

Body - Malleable iron

Gasket - Neoprene


Cover - Stamped steel

Applicable Third Party Standards


- UL Standard: 514B
- NEMA: FB-1
- UL Listed File # E207875



Female to Female

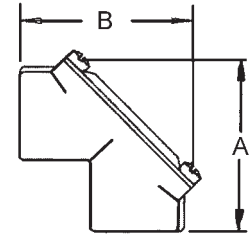

Male to Female

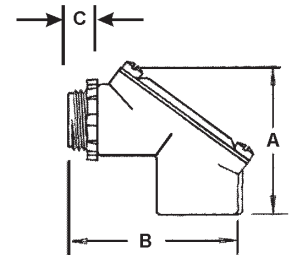

Female to Female 90°

| CATALOG NUMBER | TRADE SIZE | DIM A | DIM B | INNER PACK | MASTER PACK | WEIGHT PER C |
|----------------|------------|-------|-------|------------|-------------|--------------|
| PEF-50KON | 1/2" | 2.188 | 2.188 | 10 | 100 | 34.4 |
| PEF-75KON | 3/4" | 2.313 | 2.313 | 5 | 50 | 41.5 |
| PEF-100KON | 1" | 3.000 | 3.063 | — | 25 | 64.4 |
| PEF-125KON | 1-1/4" | 3.625 | 3.625 | — | 20 | 119.0 |
| PEF-150KON | 1-1/2" | 4.063 | 4.063 | — | 10 | 176.4 |
| PEF-200KON | 2" | 4.500 | 4.500 | — | 5 | 268.9 |

Male to Female 90°

| CATALOG NUMBER | TRADE SIZE | DIM A | DIM B | DIM C | INNER PACK | MASTER PACK | WEIGHT PER C |
|----------------|------------|-------|-------|-------|------------|-------------|--------------|
| PEM-50KON | 1/2" | 2.188 | 2.438 | 0.563 | 10 | 100 | 42.8 |
| PEM-75KON | 3/4" | 2.313 | 2.625 | 0.625 | 5 | 50 | 53.8 |
| PEM-100KON | 1" | 3.063 | 3.188 | 0.625 | — | 25 | 85.9 |
| PEM-125KON | 1-1/4" | 3.625 | 4.063 | 0.750 | — | 20 | 136.7 |
| PEM-150KON | 1-1/2" | 4.063 | 5.188 | 0.813 | — | 10 | 216.1 |
| PEM-200KON | 2" | 4.500 | 5.938 | 0.938 | — | 5 | 347.2 |