

RIGID • IMC

Set Screw Rigid Connectors Threadless for Rigid Conduit • IMC Malleable Iron



Features

- Concrete tight when taped
- Available with insulated throat
- NPSM thread 1/2" through 2"
- NPT thread above 2"
- RoHS Compliant

Standard Materials


Malleable iron
Steel locknut

Standard Finish



Zinc plated

Applicable Third Party Standards

- UL Standard: 514B
- Fed. Spec. W-F-408E
- NEMA: FB-1
- UL Listed File # E207875

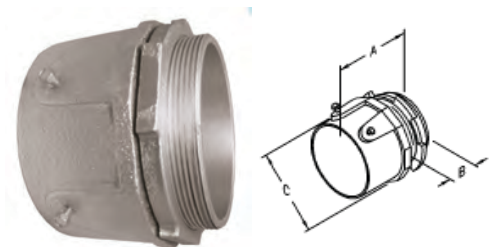

Non-Insulated

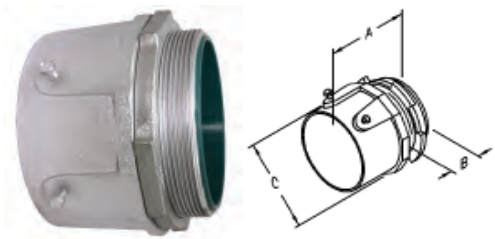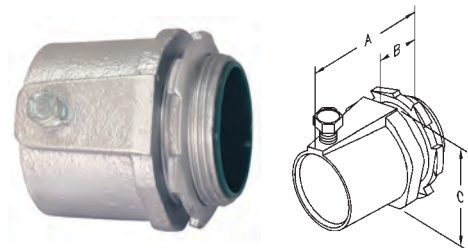

Insulated

CATALOG NUMBER	TRADE SIZE	DIM A	DIM B	DIM C	INNER PACK	MASTER PACK	WEIGHT PER C
Set Screw Rigid Connectors for Threadless Rigid Conduit and IMC							
RSC50KON	1/2"	1.375	0.438	1.313	25	250	17.4
RSC75KON	3/4"	1.688	0.5	1.563	25	100	29.6
RSC100KON	1"	1.938	0.563	1.875	5	25	42.4
RSC125KON	1-1/4"	2.188	0.625	2.188	5	25	57.5
RSC150KON	1-1/2"	2.313	0.625	2.5	5	20	78.6
RSC200KON	2"	2.438	0.625	2.938	2	10	101.8
RSC500KON*^	5"	4.688	1.375	6.5	1	1	900.0
RSC600KON*^	6"	4.938	1.5	7.5	1	1	1226.4

* Furnished with two set screws
^ 5" and 6" are NOT UL approved

CATALOG NUMBER	TRADE SIZE	DIM A	DIM B	DIM C	INNER PACK	MASTER PACK	WEIGHT PER C
Set Screw Rigid Connectors for Threadless Rigid Conduit and IMC with insulated throat							
RSC50-ICKON	1/2"	1.375	0.500	1.313	25	250	18.0
RSC75-ICKON	3/4"	1.688	0.563	1.563	25	100	26.7
RSC100-ICKON	1"	1.938	0.625	1.875	5	25	43.8
RSC125-ICKON	1-1/4"	2.188	0.688	2.188	5	25	55.7
RSC150-ICKON	1-1/2"	2.313	0.688	2.500	5	20	79.1
RSC200-ICKON	2"	2.438	0.688	2.938	2	10	92.7
RSC500-ICKON*^	5"	4.688	1.438	6.500	1	1	926.0
RSC600-ICKON*^	6"	4.938	1.563	7.500	1	1	1203.2

* Furnished with two set screws
^ 5" and 6" are NOT UL approved