

# RIGID • IMC

## One-Hole Straps for Rigid Conduit • IMC Malleable Iron



### Features

- Heavy duty casting
- RoHS compliant

### Standard Materials


Malleable iron

### Standard Finish

Zinc plated

### Applicable Third Party Standards

- UL Standard: 2239
- UL Listed File # E213669

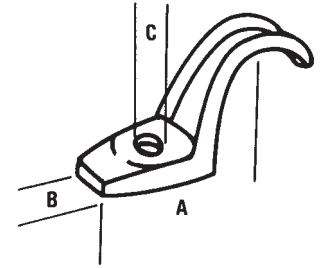

CATALOG NUMBER	TRADE SIZE	DIM A	DIM B	DIM C	MASTER PACK	WEIGHT PER C
ST50KON	1/2"	1.438	0.625	0.313	100	6.2
ST75KON	3/4"	1.750	0.750	0.313	100	7.5
ST100KON	1"	1.875	0.875	0.313	500	9.2
ST125KON	1-1/4"	2.375	1.000	0.438	100	21.7
ST150KON	1-1/2"	2.750	1.250	0.438	50	31.8
ST200KON	2"	3.250	1.375	0.563	50	44.2
ST250KON	2-1/2"	3.250	1.375	0.563	25	66.3
ST300KON	3"	5.188	1.750	0.563	10	103.2
ST350KON	3-1/2"	5.500	2.125	0.750	10	185.0
ST400KON	4"	6.500	2.250	0.750	10	221.0
ST500KON	5"	7.375	2.688	0.750	5	368.8
ST600KON	6"	8.625	3.125	1.125	5	631.3