

LIQIDTIGHT

Screw On Type Straight Connectors for use with Liquidtight Flexible Metallic Conduit Malleable Iron

Features

- No disassembly required for installation of Screw On Liquidtight
- Tapered threaded male hub - NPT
- Compact, slim diameter
- Liquidtight/Raintight/Oiltight
- Suitable for wet locations
- Long ferrule prevents pullout & tight bend conduit pop out
- RoHS compliant

Standard Materials

- Malleable iron
- Nylon
- Steel ferrule
- Steel locknut

Standard Finish

- Zinc plated


Applicable Third Party Standards

- UL Standard: 514B
- Fed. Spec. W-F-408E
- NEMA: FB-1
- UL Listed File # E207875


U.S. Patent No. 7.914.048



Non-Insulated

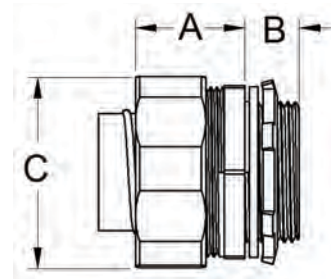

Insulated

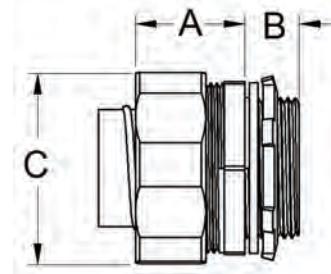

LIQIDTIGHT

CATALOG NUMBER	TRADE SIZE	KO SIZE	DIM A	DIM B	DIM C	MASTER PACK	WEIGHT PER C
Non-Insulated							
LTQ38KON	3/8"	1/2"	1.125	0.500	1.125	25	15.4
LTQ50KON	1/2"	1/2"	1.250	0.500	1.250	25	17.6
LTQ75KON	3/4"	3/4"	1.250	0.500	1.563	25	28.7
LTQ100KON	1"	1"	1.438	0.625	1.813	5	39.7
LTQ125KON	1-1/4"	1-1/4"	1.500	0.688	2.250	5	55.1
LTQ150KON	1-1/2"	1-1/2"	1.625	0.750	2.438	2	70.5
LTQ200KON	2"	2"	1.475	0.750	3.000	1	99.2
Insulated							
LTQ38-ICKON	3/8"	1/2"	1.125	0.563	1.125	25	15.6
LTQ50-ICKON	1/2"	1/2"	1.250	0.563	1.250	25	17.8
LTQ75-ICKON	3/4"	3/4"	1.250	0.563	1.563	25	28.9
LTQ100-ICKON	1"	1"	1.438	0.688	1.813	5	40.1
LTQ125-ICKON	1-1/4"	1-1/4"	1.500	0.750	2.250	5	55.7
LTQ150-ICKON	1-1/2"	1-1/2"	1.625	0.813	2.438	2	71.2
LTQ200-ICKON	2"	2"	1.750	0.813	3.000	1	100.2