

# LIQIDTIGHT

Screw On 90° Connectors for use with Liquidtight Flexible Metallic Conduit • Malleable Iron



## Features

- No disassembly required for installation of Screw On Liquidtight
- Tapered threaded male hub - NPT
- Compact, slim diameter
- Liquidtight/Raintight/Oiltight
- Suitable for wet locations
- Long ferrule prevents pullout & tight bend conduit pop out
- RoHS compliant

## Standard Materials

- Malleable iron
- Nylon
- Steel ferrule
- Steel locknut

## Standard Finish

- Zinc plated


## Applicable Third Party Standards

- UL Standard: 514B
- Fed. Spec. W-F-408E
- NEMA: FB-1
- UL Listed File # E207875


U.S. Patent No. 7.914.048



Non-Insulated

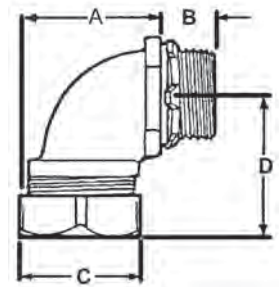

Insulated

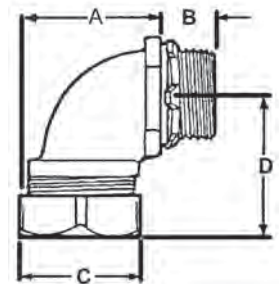

LIQIDTIGHT

CATALOG NUMBER	TRADE SIZE	KO SIZE	DIM A	DIM B	DIM C	DIM D	MASTER PACK	WEIGHT PER C
90° Non-Insulated								
LQ3890KON	3/8"	1/2"	1.313	0.500	1.125	1.625	25	25.4
LQ5090KON	1/2"	1/2"	1.438	0.500	1.250	1.625	25	28.9
LQ7590KON	3/4"	3/4"	1.625	0.500	1.563	1.750	10	44.1
LQ10090KON	1"	1"	2.313	0.625	1.813	2.125	10	74.5
90° Insulated								
LQ3890-ICKON	3/8"	1/2"	1.313	0.563	1.125	1.625	25	25.7
LQ5090-ICKON	1/2"	1/2"	1.438	0.563	1.250	1.625	25	29.2
LQ7590-ICKON	3/4"	3/4"	1.625	0.563	1.563	1.750	10	44.6
LQ10090-ICKON	1"	1"	2.313	0.689	1.813	2.125	10	75.3

Sizes available up to 2"