


52103105	DATA SHEET	
Valid from: 14.04.2023	SKINDICHT® BL-M with O-Ring	

SKINDICHT® BL-M blind plugs are used wherever already existing housing holes are not yet required or no longer required. Our blind plug model is equipped with a screwing slit, which makes installation significantly easier. The SKINDICHT® BL-M is qualified for using by machine-, apparatus construction and drives.



Components:

Blind plug	Brass, nickel-plated Brass lead free, nickel-plated
O-Ring	NBR

Technical features:

Connecting thread	M12x1,5 up to M75 x1,5 acc. to EN 60423
Protection class	IP68 (10bar/30min) acc. to EN 60529
Temperature range	-20 °C up to +100 °C


Norm references:



File No.: e79903

(except size M75x1,5)

M	Ø A [mm]	C [mm]	D [mm]	O-Ring [mm]	Article No.	
					Brass	Brass lead free
M12x1,5	14	7,5	5	9 x 2	52103105	52103105LF
M16x1,5	18	8	5	13 x 2	52103115	52103115LF
M20x1,5	22	9,5	6	17 x 2	52103125	52103125LF
M25x1,5	28	11	7	22 x 2	52103135	52103135LF
M32x1,5	35	12	8	28 x 2	52103145	52103145LF
M40x1,5	44	13	9	36 x 2	52103155	52103155LF
M50x1,5	54	15	9	46 x 2	52103165	-
M63x1,5	70	16	10	57 x 2	52103175	-
M75x1,5	80	17	11	65 x 2	52103195	-

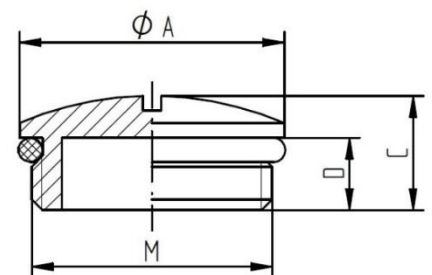

For more information please see our current catalogue. Please do not hesitate to contact our laboratory if there are any questions regarding resistance against aggressive agents and special oil.

Creator: T. Dvoulety /PDP Released: DAMU1/PDP	Document: DB52103105EN Version: 07	Page 1 of 1
--	---------------------------------------	-------------