

**Part no.: 50114517**  
**KB 232-1 IT190x**  
**Interconnection cable**

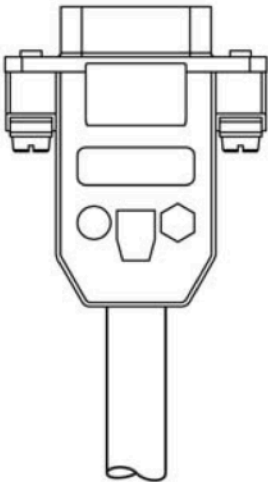


Figure can vary

## Contents

- Technical data
- Electrical connection

Part no.: 50114517 – KB 232-1 IT190x – Interconnection cable

## Technical data

### Basic data

Suitable for	IT 1300 series mobile bar code readers IT 1911 series mobile 2D-code readers IT 1902 series mobile 2D-code readers IT 1900 series mobile 2D-code readers IT 1910 series mobile 2D-code readers
Suitable for interface	TTL RS 232

### Connection

#### Connection 1

Type of connection	Sub-D
Type	Female
No. of pins	9 -pin
Design	Axial

#### Connection 2

Type of connection	RJ41
--------------------	------

#### Connection 3

Type of connection	Connector
Thread size	Pluggable
Type	Female
No. of pins	2 -pin
Design	Axial

#### Cable properties

Sheathing color	Black
Shielded	Yes
Cable design	Helix cable
Cable diameter (external)	5 mm
Cable length	3,000 mm
Sheathing material	PVC

### Classification

eCl@ss 8.0	27279218
eCl@ss 9.0	27060311
ETIM 5.0	EC001855

## Electrical connection

Connection 1	
Type of connection	Sub-D
Type	Female
No. of pins	9 -pin
Design	Axial

Connection 2	
Type of connection	RJ41

Part no.: 50114517 – KB 232-1 IT190x – Interconnection cable

Connection 3	
Type of connection	Connector
Thread size	Pluggable
Type	Female
No. of pins	2 -pin
Design	Axial