

Part no.: 50128800
KB 232-3 IT190x
Interconnection cable

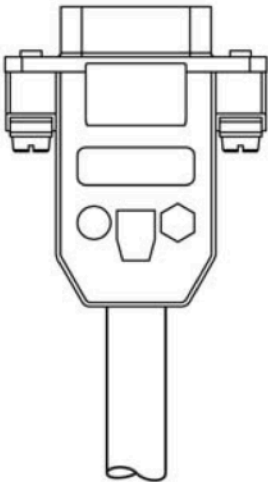


Figure can vary

Contents

- Technical data
- Electrical connection

Part no.: 50128800 – KB 232-3 IT190x – Interconnection cable

Technical data

Basic data

Suitable for	IT 1911 series mobile 2D-code readers IT 1300 series mobile bar code readers IT 1902 series mobile 2D-code readers IT 1900 series mobile 2D-code readers IT 1910 series mobile 2D-code readers
Suitable for interface	RS 232 TTL

Connection

Connection 1

Type of connection	Sub-D
Type	Female
No. of pins	9 -pin
Design	Axial

Connection 2

Type of connection	RJ41
--------------------	------

Connection 3

Type of connection	Connector
Thread size	Pluggable
Type	Female
No. of pins	2 -pin
Design	Axial

Cable properties

Sheathing color	Black
Shielded	Yes
Cable design	Smooth
Cable diameter (external)	5 mm
Cable length	5,000 mm
Sheathing material	PVC

Classification

eCl@ss 8.0	27279218
eCl@ss 9.0	27060311
ETIM 5.0	EC001855

Electrical connection

Connection 1	
Type of connection	Sub-D
Type	Female
No. of pins	9 -pin
Design	Axial

Connection 2	
Type of connection	RJ41

Part no.: 50128800 – KB 232-3 IT190x – Interconnection cable

Connection 3	
Type of connection	Connector
Thread size	Pluggable
Type	Female
No. of pins	2 -pin
Design	Axial