


en 05-2014/08 50112701




- Configurable with screw terminals or insulation displacement technology
- Very good resistance against oil, cooling agents, lubricants, and chemicals
- Protection class IP 67

**Dimensioned drawing**


M8 connector, axial, 3-/4-pin  
**D M8A-3P-SK**  
**D M8A-4P-SK**

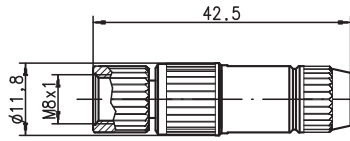


M12 connector, axial, 4-pin  
**KD 095-4A**

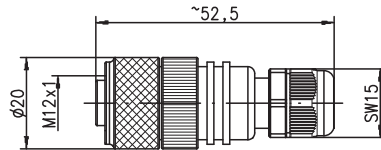


M12 connector, angular, 4-pin  
**KD 095-4**

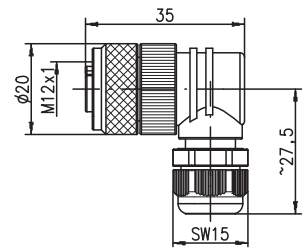


M12 cable plug, axial, 4-/5-pin  
**KS 095-4A**  
**KS 095-5A**

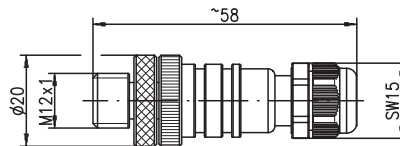

M12 connector, axial, 5-pin  
**KD 095-5A**  
**KD 095-5A-PG9**

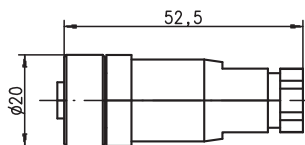


M12 connector, angular, 5-pin  
**KD 095-5**

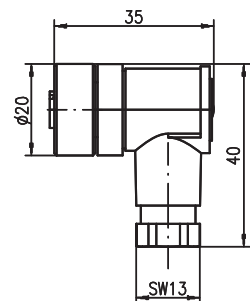


**Contact arrangement**

 
**M8 connector, 3-pin**



**M12 connector, 4-pin**

 


**M12 cable plug, 4-pin**

 


**M8 connector, 4-pin**



 **M12 connector, 5-pin**



**M12 cable plug, 5-pin**

 

1) only 4-pin M12 connectors and 5-pin M12 plug



We reserve the right to make changes • DS\_Accessory/KDKS\_en\_50112701.fm

## Specifications

### Electrical data

Operating voltage

### M8 connector

≤ 32VAC/DC

### M12 connector

4-pin: ≤ 250VAC/DC

5-pin: ≤ 125VAC/DC

Operating current

≤ 4A per contact

≤ 4A per contact

Insulation grade

category II acc. to IEC 60664-1

category II acc. to IEC 60664-1

### Mechanical data

Connection type

insulation displacement technology

screw connection

Conductor cross-section

0.14 ... 0.34mm<sup>2</sup>

0.14 ... 0.75mm<sup>2</sup>

Sheath diameter

2.5 ... 5.1 mm (black seal)

3.0 ... 6.5mm

PG9: 4.0 ... 8.0mm

### Environmental data

Operating temperature range

-25°C ... +85°C

## Tables

## Diagrams

## Order guide

### M8 connector

Designation	Part No.	Design	Contacts	Connection type	Other features
D M8A-3P-SK	50104582	axial socket	3	insulation displacement technology	
D M8A-4P-SK	50104583	axial socket	4	insulation displacement technology	

### M12 connector

Designation	Part No.	Design	Contacts	Connection type	Other features
KD 095-4A	50031323	axial socket	4	screw connection	cURus
KD 095-4	50031324	angular socket	4	screw connection	cURus
KS 095-4A	50040155	axial plug	4	screw connection	cURus
KD 095-5A	50020501	axial socket	5	screw connection	
KD 095-5	50020502	angular socket	5	screw connection	
KD 095-5A-PG9	50081461	axial socket	5	screw connection	for cables Ø 4 ... 8mm
KS 095-5A	50114223	axial plug	5	screw connection	cURus

## Remarks