



Part no.: 50081283
TKS 20X40
Reflector

Figure can vary

Contents

- Technical data
- Dimensioned drawings
- Accessories



Part no.: 50081283 – TKS 20X40 – Reflector

Technical data

Mechanical data	
Design	Rectangular
Mounting dimension, width	20 mm
Reflection surface width	16 mm
Mounting dimension, height	60 mm
Reflection surface height	38 mm
Mounting dimension, thickness	6 mm
Triple reflector size	2.3 mm
Reflector material	Plastic
Material of base material	Plastic
Chemical designation, reflector material	PMMA8N
Structure, active surface	Triple
Net weight	5 g
Type of fastening	Through-hole mounting Adhesive


Environmental data	
Ambient temperature, operation	-40 ... 70 °C

Certifications	
Degree of protection	IP 67

Classification	
eCl@ss 8.0	27279203
eCl@ss 9.0	27273601
ETIM 5.0	EC002467

Dimensioned drawings

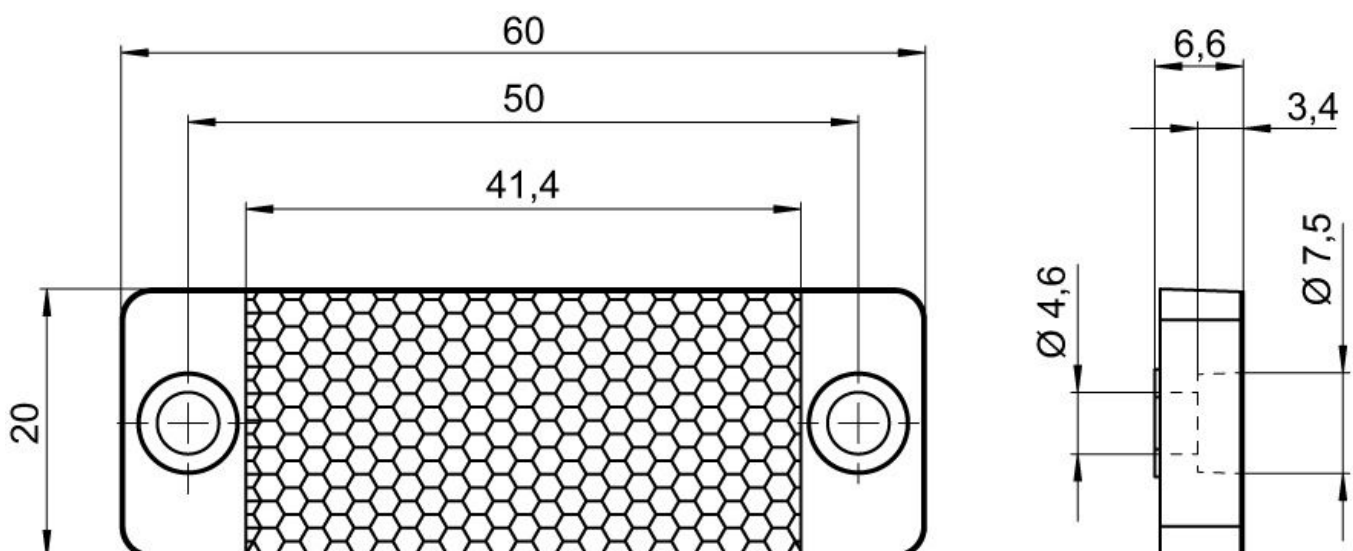


All dimensions in millimeters



Part no.: 50081283 – TKS 20X40 – Reflector

Accessories

Mounting technology - Rod mounts

	Part no.	Designation	Article	Description
	50082084	BT 450.1-96	Mounting device	Design of mounting device: Mounting system Mounting bracket, at system: For 10 mm rod Mounting bracket, at device: Screw type Type of mounting device: Turning, 360°, Adjustable Material: Metal
	50122797	BTU 346M-D12	Mounting system	Contains: 2x M4 x 25 screw, 2x position washers Design of mounting device: Mounting system Mounting bracket, at system: For 12 mm rod, Sheet-metal mounting Mounting bracket, at device: Screw type Type of mounting device: Turning, 360°, Clampable, Adjustable Material: Metal
	50122798	BTU 346M.5-D12	Mounting system	Design of mounting device: Mounting system Mounting bracket, at system: For 12 mm rod, Sheet-metal mounting Mounting bracket, at device: Screw type Type of mounting device: Turning, 360°, Clampable, Adjustable Material: Stainless steel
	50129149	BTU 346M.6-D12	Mounting system	Design of mounting device: Mounting system Mounting bracket, at system: For 12 mm rod, Sheet-metal mounting Mounting bracket, at device: Screw type Type of mounting device: Turning, 360°, Adjustable, Clampable Material: Metal, Stainless steel