





Product designation				Reversing contactor
Product type designation				BGT09
<b>Electrical features</b>				
Maximum operating current (=440V)			A	9
<b>Contact characteristics</b>				
Operational current Ie	AC-3 (=440V =55°C)		A	9
<b>Rated operational power AC-3 (T=55°C)</b>				
	230V	kW	2.2	
	400V	kW	4	
	415V	kW	4.3	
	440V	kW	4.5	
	500V	kW	5	
	690V	kW	5	
<b>Built-in auxiliary contacts</b>				
	NO		1	
	NC		0	
<b>UL technical data</b>				
<b>Maximum UL/CSA horsepower ratings single-phase</b>				
	110V-120V	HP	0.5	
	220V-240V	HP	1.5	
<b>Maximum UL/CSA horsepower ratings three-phase, 3-pole</b>				
	200V-208V	HP	2	
	220V-240V	HP	3	
	440V-480V	HP	5	
	550V-600V	HP	5	
<b>Mechanical features</b>				
Terminals type				Clamp screw
Weight				g 380
<b>Dimensions</b>				

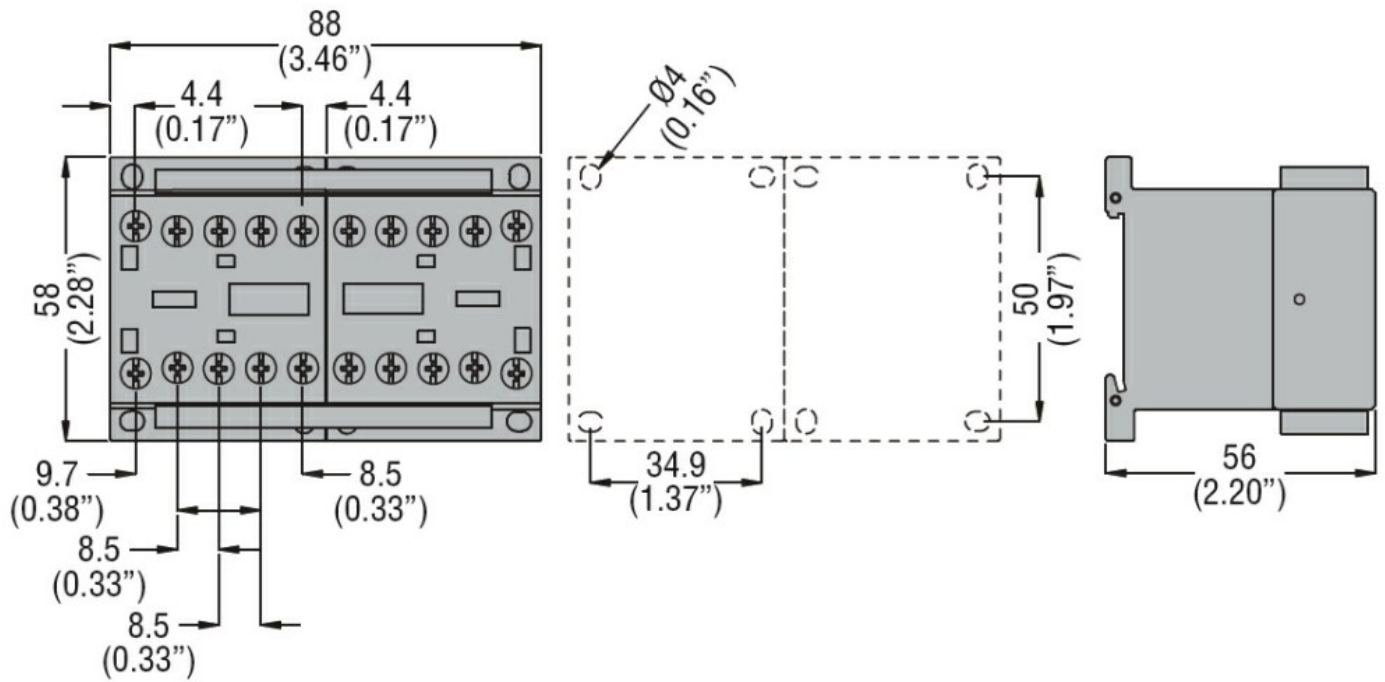

Wiring diagrams

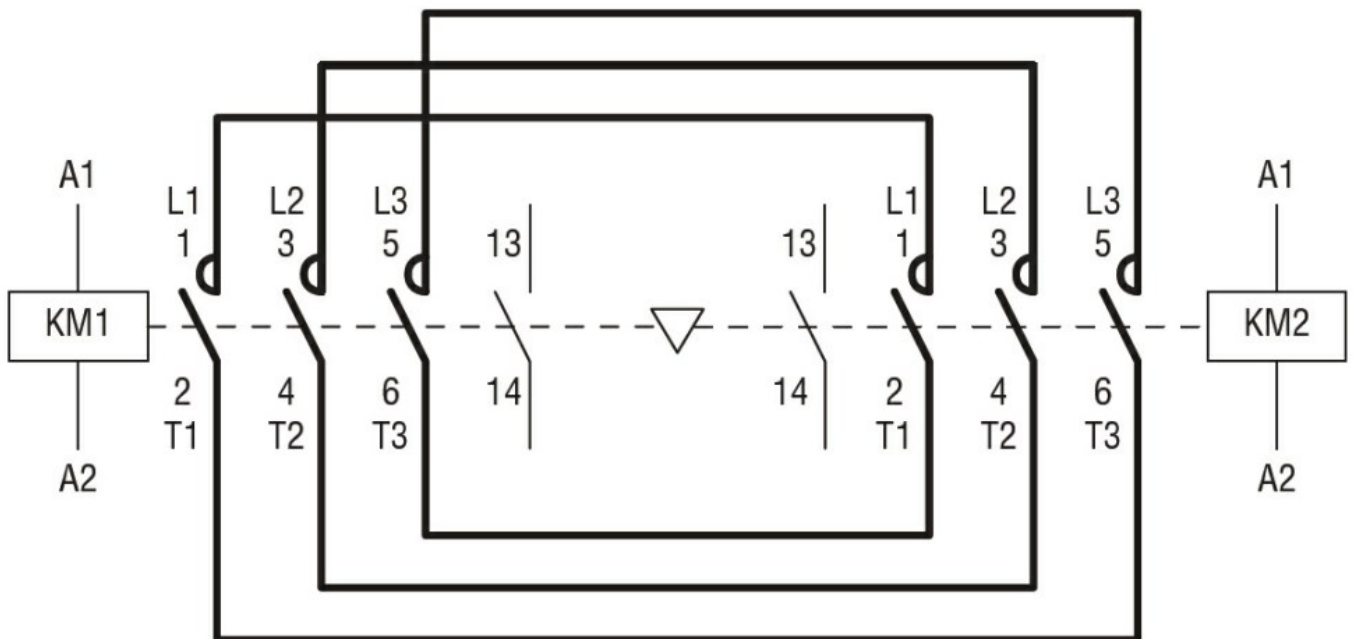

Certifications and compliance

Compliance

IEC/EN 60947-1  
 IEC/EN 60947-4-1  
 UL508 CSA C22.2 n° 14

Certificates

cULus

ETIM classification

ETIM 8.0

EC001037 -  
 Motor  
 starter/Motor  
 starter  
 combination

