




Product designation			LED elements steady light	
Product type designation			8LM2TL	
General characteristics				
Colour			Red	
Electrical characteristics				
Rated frequency			Hz	50/60
Supply voltage (AC)			V	85...140
Operations				
Electrical life			hours	100000
Mechanical features				
Tightening torque for terminals max			Nm	1
Conductor section				
AWG/kcmil conductor section			max	12
IEC			max	mm ² 1 or 2 2.5
Mounting adapter				
Weight			g	16
Ambient conditions				
Temperature				
Operating temperature			min	°C -25
			max	°C +60
Storage temperature			min	°C -40
			max	°C +85
Dimensions				



Wiring diagrams

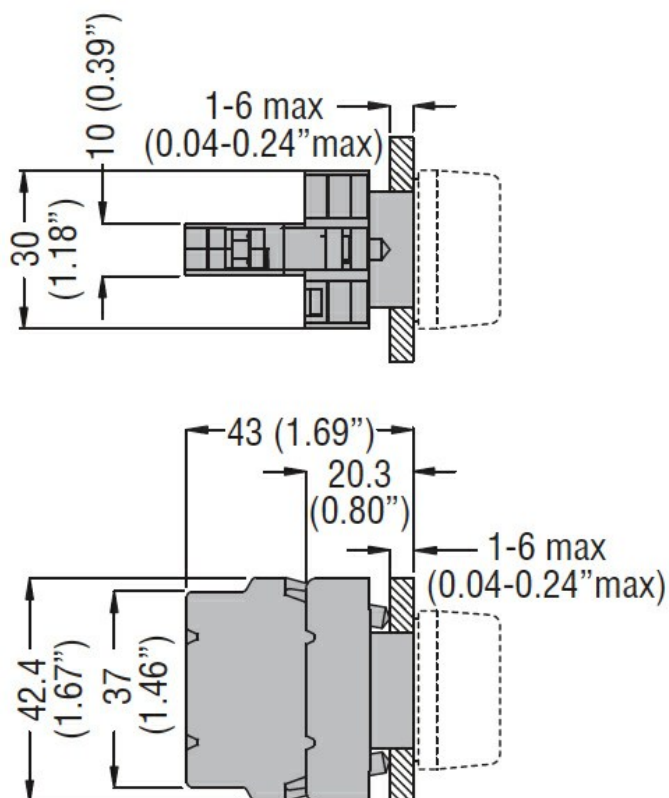

Certifications and compliance

Compliance

CSA C22.2 n° 14
IEC/EN 60947-1
IEC/EN 60947-5-1
UL508

Certificates

CCC
cULus
EAC

ETIM classification

ETIM 8.0

EC000204 -
Lamp holder
block for control
circuit devices