





Product designation				Signal tower	
Product type designation				Ø45mm/1.7"	
8TL4					
General characteristics					
Diameter				mm - inch	45 / 1.77
Supply voltage (DC)				V	24±10%
Colour				Green, orange, red	
IEC degree of protection				IP54	
Light consumption per module (DC)				mA	37
Mechanical features					
Tightening torque for terminals max				Nm	0.5
Terminals screw				Screw clamp terminals	
Conductor section					
AWG/Kcmil		max		16	
IEC		max		mm²	
				1.5	
Weight				g	240
Ambient conditions					
Temperature					
Operating temperature		min		°C	
				-20	
		max		°C	
				+50	
Dimensions					

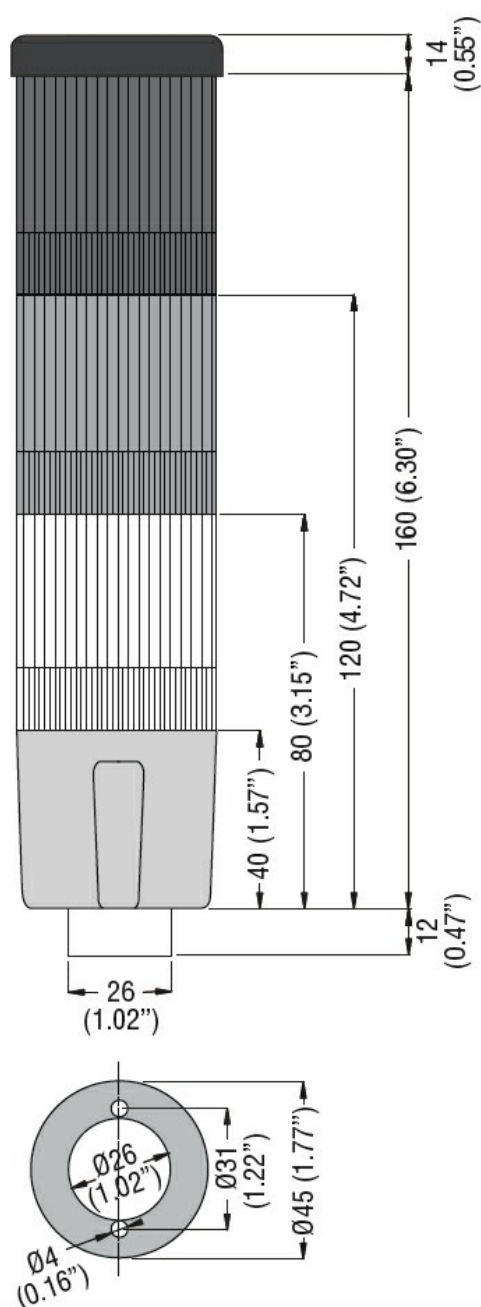

Wiring diagrams

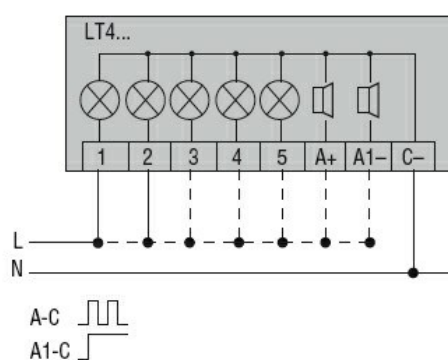

Certifications and compliance

Compliance

CSA C22.2 n° 14

IEC/EN 60947-1

IEC/EN 60947-5-1

UL508

Certificates

cULus

EAC

ETIM classification

ETIM 8.0

EC001042 -
Signal tower
complete