





Product designation			Remote display unit		
Product type designation			EXCRDU1		
General characteristics					
Description			Remote display unit, graphic LCD, touch screen 128x112 pixels, IP65 protection. Compatible with ADXL... soft starter and VLB3... variable speed drives		
Functions			Remote display unit		
Rated power supply voltage			Auxiliary supply 100...240VAC/12...24VDC		
Monitoring method					
Device compatibility			ADXL soft starter and VLB3 variable speed drives		
Interface					
RS485 communication			Yes		
Mechanical features					
Conductor cross section			min	mm²	0.2
			Max	mm²	2.5
			min	AWG	24 / 18 for UL/CSA
			Max	AWG	12
Tightening torque (Max)				Nm	0.56
				lbin	4.5
Dimensions					

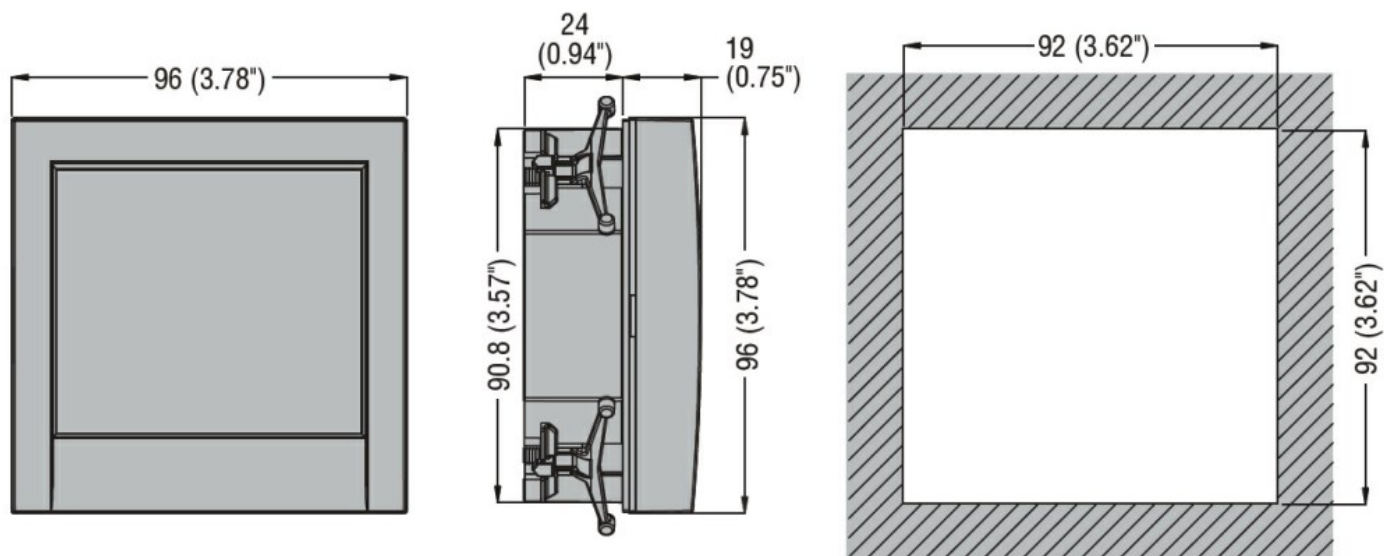

Wiring diagrams

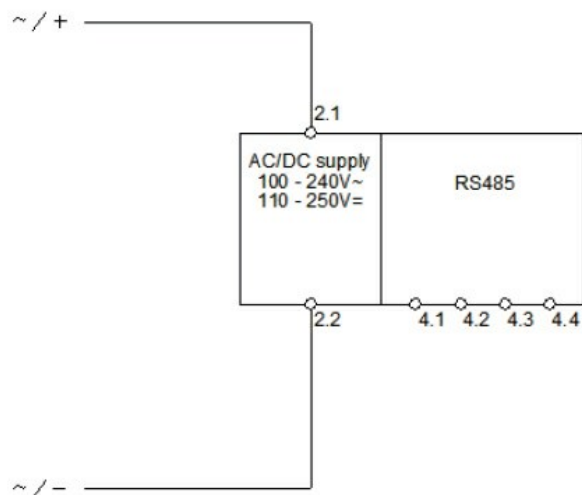

Certifications and compliance

Compliance

C22.2-n°14-95

IEC/EN 61000-6-2

IEC/EN 61000-6-4

UL508

Certificates

cULus

EAC

ETIM classification

ETIM 8.0

EC002498 -
Accessories/spare
parts for low-
voltage switch
technology