



Product designation

Pushbutton  
actuators, spring  
return, with  
symbol  
LPCB11

Product type designation

#### General characteristics

|                          |                      |
|--------------------------|----------------------|
| Colour                   | White                |
| Type of positions        | Flush                |
| Material                 | Polyamide            |
| IEC degree of protection | IP66, IP67 and IP69K |

#### Mechanical features

|                  |        |                          |
|------------------|--------|--------------------------|
| Operating force  | kg-lb  | <0.5Kg / 1.1lb           |
| Mechanical life  | cycles | 5000000                  |
| Fixing           |        | Without mounting adapter |
| Mounting adapter |        | LPXAU120                 |
| Weight           | g      | 25                       |

#### UL technical data

|                         |                              |
|-------------------------|------------------------------|
| UL degree of protection | Type1, 2, 3R, 4, 4X, 12, 12K |
|-------------------------|------------------------------|

#### Ambient conditions

Temperature


Operating temperature

|     |    |     |
|-----|----|-----|
| min | °C | -25 |
| max | °C | +70 |

Storage temperature

|     |    |     |
|-----|----|-----|
| min | °C | -40 |
| max | °C | +85 |

#### Dimensions

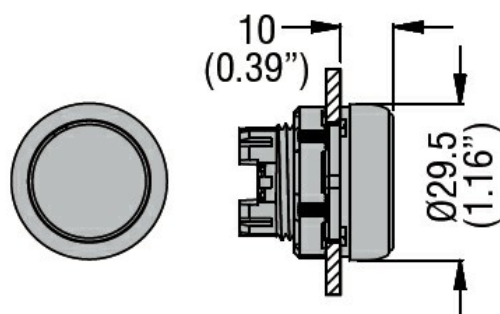

#### Certifications and compliance

Compliance

CSA C22.2 n° 14  
IEC/EN/BS 60947-1  
IEC/EN/BS 60947-5-1

---

UL508

---

Certificates

CCC

cULus

EAC

RINA

ETIM classification

ETIM 8.0

EC000221 -  
Front element for  
push button