



Mushroom head
pushbutton,
Latch, turn key to
release Ø
40mm/1.6"
LPCB684

Product designation

Product type designation

General characteristics

Colour	Black
Material	Polyamide
IEC degree of protection	IP66, IP67 and IP69K

Mechanical features

Operating force	kg-lb	<0.5Kg / 1.1lb
Mechanical life - spring return actuators	cycles	5000000
Mechanical life - Latch actuators	cycles	300000
Mounting adapter		LPXAU120
Weight	g	83

UL technical data

UL degree of protection	Type1, 2, 3R, 4, 4X, 12, 12K
-------------------------	------------------------------

Ambient conditions

Temperature


Operating temperature

min	°C	-25
max	°C	+70

Storage temperature

min	°C	-40
max	°C	+85

Dimensions

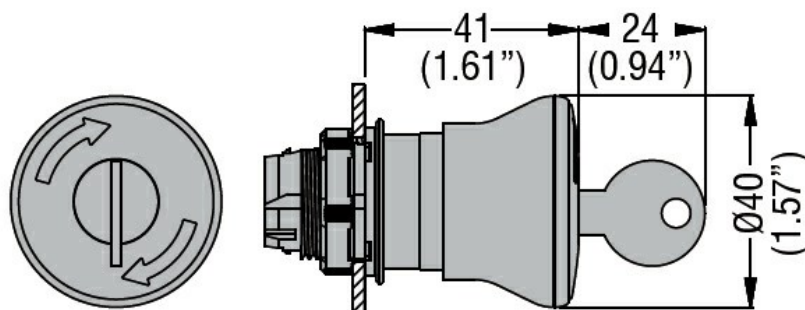

Certifications and compliance

Compliance

CSA C22.2 n° 14
IEC/EN/BS 60947-1
IEC/EN/BS 60947-5-1
UL508

Certificates

MUSHROOM HEAD PUSHBUTTON ACTUATOR Ø22MM PLATINUM SERIES CHROMED
PLASTIC, LATCH, TURN KEY TO RELEASE, Ø40MM. FOR NORMAL STOPPING. BLACK.
DIFFERENT KEY CODE

CCC	
cULus	
EAC	
RINA	
UL	

ETIM classification

ETIM 8.0

EC001038 -
Front element for
mushroom push-
button