



Double-touch
actuators, spring
return white
indicator - One
extended and
one flush
pushbuttons
LPCBL72

Product designation

Product type designation

General characteristics

Colour	Black/Red
Type of positions	I - O
Material	Polyamide
IEC degree of protection	IP66, IP67 and IP69K

Mechanical features

Operating force	kg-lb	<0.5Kg / 1.1lb
Mounting adapter		L PXAU120
Weight	g	30

UL technical data

UL degree of protection	Type1, 2, 3R, 4, 4X, 12, 12K
-------------------------	------------------------------

Ambient conditions

Temperature


Operating temperature

min	°C	-25
max	°C	+70

Storage temperature

min	°C	-40
max	°C	+85

Dimensions

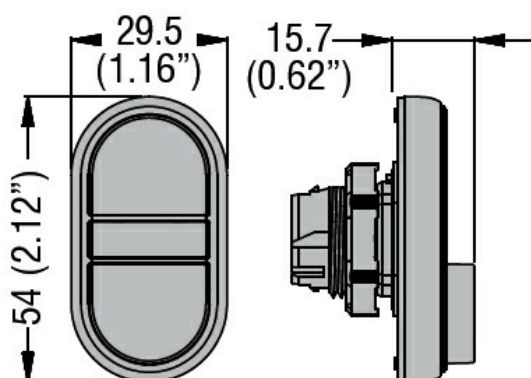

Certifications and compliance

Compliance

CSA C22.2 n° 14
IEC/EN/BS 60947-1

DOUBLE-TOUCH ACTUATOR, SPRING RETURN, WHITE INDICATOR Ø22MM PLATINUM
 SERIES CHROMED PLASTIC, 1 EXTENDED AND 1 FLUSH PUSHBUTTONS. BOTH SPRING
 RETURN, BLACK - RED/I - 0

IEC/EN/BS 60947-5-1

UL508

Certificates

CCC

cULus

EAC

RINA

ETIM classification

ETIM 8.0

EC000221 -
 Front element for
 push button