



Product designation

Product type designation

General characteristics

Colour	Red		
Type of positions	Extended. Adjustable length 0...150mm/5.9in		
Material	Polyamide		
IEC degree of protection	IP66, IP67 and IP69K		

Mechanical features

Operating force	kg-lb	<0.5Kg / 1.1lb	
Mechanical life	cycles	5000000	
Fixing		Without mounting adapter	
Mounting adapter		LPXAU120	
Weight	g	40	

UL technical data

UL degree of protection	Type1, 2, 3R, 4, 4X, 12, 12K		
-------------------------	---------------------------------	--	--

Ambient conditions

Temperature


Operating temperature

min	°C	-25
max	°C	+70

Storage temperature

min	°C	-40
max	°C	+85

Dimensions

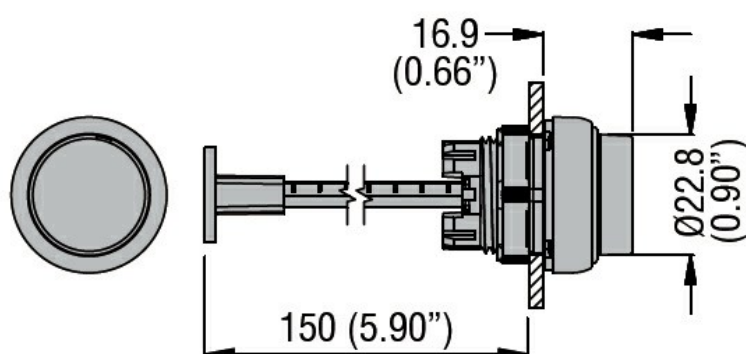

Certifications and compliance

Compliance

CSA C22.2 n° 14

MECHANICAL RESET BUTTON, COMPLETE UNIT, SPRING RETURN Ø22MM PLATINUM
SERIES CHROMED PLASTIC, EXTENDED. ADJUSTABLE LENGTH 0...150MM/5.9IN, RED

IEC/EN/BS 60947-1
IEC/EN/BS 60947-5-1
UL508

Certificates

CCC
cULus
EAC
RINA

ETIM classification

ETIM 8.0

EC000221 -
Front element for
push button