



USB interface,  
A/A female type  
connection  
LPFD0

Product designation

Product type designation

### General characteristics

Material

Aluminium and  
zinc alloy for the  
metal part,  
polyamide for  
plastic parts

IEC degree of protection

IP66, IP67 and  
IP69K

### UL technical data

UL degree of protection

1, 2, 3R, 4, 4X,  
12, 12K on front

### Ambient conditions

Temperature


Operating temperature

|     |    |     |
|-----|----|-----|
| min | °C | -25 |
| max | °C | +70 |

Storage temperature

|     |    |     |
|-----|----|-----|
| min | °C | -40 |
| max | °C | +85 |

### Dimensions

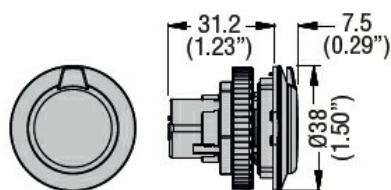

### Certifications and compliance

Compliance

CSA C22.2 n° 14  
IEC/EN/BS 60947-1  
IEC/EN/BS 60947-5-1  
UL508

Certificates

cULus

### ETIM classification

ETIM 8.0

EC002780 -  
Interface module