



Selector switch  
actuators long  
lever - 2 position  
LPFS22

## Product designation

## Product type designation

### General characteristics

|                          |                          |
|--------------------------|--------------------------|
| Colour                   | Black                    |
| Type of positions        | 0 - 1                    |
| Material                 | Aluminium and zinc alloy |
| IEC degree of protection | IP66, IP67 and IP69K     |

### Mechanical features

|                  |                          |         |
|------------------|--------------------------|---------|
| Mechanical life  | cycles                   | 1000000 |
| Fixing           | Without mounting adapter |         |
| Mounting adapter | LPXAU120M                |         |

### UL technical data

|                         |                              |
|-------------------------|------------------------------|
| UL degree of protection | Type1, 2, 3R, 4, 4X, 12, 12K |
|-------------------------|------------------------------|

### Ambient conditions

#### Temperature


##### Operating temperature

|     |    |     |
|-----|----|-----|
| min | °C | -25 |
| max | °C | +70 |

##### Storage temperature

|     |    |     |
|-----|----|-----|
| min | °C | -40 |
| max | °C | +85 |

### Dimensions

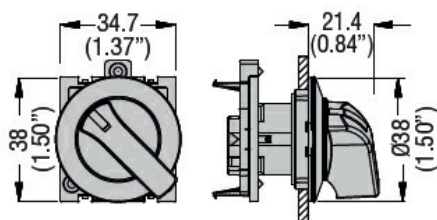

Long lever

### Certifications and compliance

#### Compliance

|                     |
|---------------------|
| CSA C22.2 n° 14     |
| IEC/EN/BS 60947-1   |
| IEC/EN/BS 60947-5-1 |
| UL508               |

#### Certificates

cULus

### ETIM classification

ETIM 8.0

EC002611 -  
Control switch