




Product designation				Selector switch actuator key - 3 position	
Product type designation				LPFS33	
General characteristics					
Colour				Black	
Type of positions				1 - 0 - 2, key extraction in 1 and 0 and 2	
Material				Aluminium and zinc alloy	
IEC degree of protection				IP66, IP67 and IP69K	
Mechanical features					
Mechanical life			cycles	1000000	
Fixing				Without mounting adapter	
Mounting adapter				LPXAU120M	
UL technical data					
UL degree of protection				Type1, 2, 3R, 4, 4X, 12, 12K	
Ambient conditions					
Temperature					
Operating temperature		min	°C	-25	
		max	°C	+70	
Storage temperature		min	°C	-40	
		max	°C	+85	

Dimensions

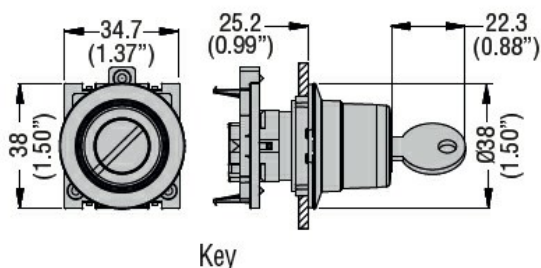

Certifications and compliance

Compliance		CSA C22.2 n° 14
		IEC/EN/BS 60947-1
		IEC/EN/BS 60947-5-1
		UL508
Certificates		cULus

ETIM classification

ETIM 8.0

EC002611 -
Control switch