




Product designation				Selector switch actuator key - 3 position		
Product type designation				LPFS33		
General characteristics						
Colour				Black		
Type of positions				1 - 0 - 2, key extraction in 1 and 0 and 2		
Material				Aluminium and zinc alloy for the metal part, polyamide for plastic parts		
IEC degree of protection				IP66, IP67 and IP69K		
Mechanical features						
Mechanical life			cycles	1000000		
Fixing				Without mounting adapter		
Mounting adapter				LPXAU120M		
UL technical data						
UL degree of protection				Type1, 2, 3R, 4, 4X, 12, 12K		
Ambient conditions						
Temperature						
		Operating temperature		min	°C	-25
				max	°C	+70
		Storage temperature		min	°C	-40
				max	°C	+85

Dimensions

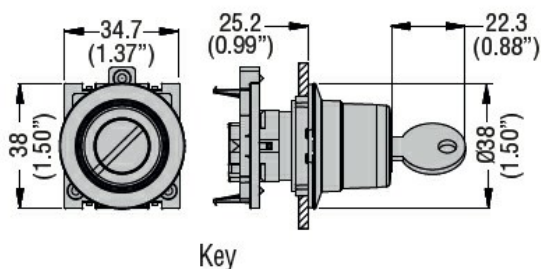

Certifications and compliance

Compliance

CSA C22.2 n° 14
IEC/EN/BS 60947-1
IEC/EN/BS 60947-5-1

UL508

Certificates

cULus

ETIM classification

ETIM 8.0

EC002611 -
Control switch