



Mushroom head
pushbutton,
spring return Ø
40mm/1.6"
LPSB614

Product designation

Product type designation

General characteristics

Colour	Green
Material	Aluminium and zinc alloy for metal parts and polyamide for plastic parts
IEC degree of protection	IP66, IP67 and IP69K

Mechanical features

Fixing	Without mounting adapter
Mounting adapter	LPXAU120M


UL technical data

UL degree of protection	Type1, 2, 3R, 4, 4X, 12, 12K
-------------------------	------------------------------

Ambient conditions

Temperature			
Operating temperature			
	min	°C	-25
	max	°C	+70
Storage temperature			
	min	°C	-40
	max	°C	+85

Dimensions

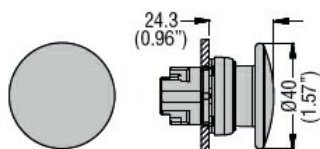

Certifications and compliance

Compliance	
	CSA C22.2 n° 14
	IEC/EN/BS 60947-1
	IEC/EN/BS 60947-5-1
	UL508
Certificates	
	cULus

ETIM classification

ETIM 8.0

EC000221 -
Front element for
push button