



Double-touch
actuators, spring
return - One
extended and
one flush
pushbuttons
LPSB72

Product designation

Product type designation

General characteristics

Colour	White/Black
Material	Aluminium and zinc alloy for metal parts and polyamide for plastic parts
IEC degree of protection	IP66, IP67 and IP69K

Mechanical features

Fixing	Without mounting adapter
Mounting adapter	LPXAU120M


UL technical data

UL degree of protection	Type1, 2, 3R, 4, 4X, 12, 12K
-------------------------	------------------------------

Ambient conditions

Temperature			
Operating temperature			
	min	°C	-25
	max	°C	+70
Storage temperature			
	min	°C	-40
	max	°C	+85

Dimensions

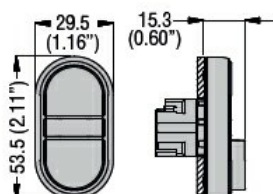

Certifications and compliance

Compliance	
	CSA C22.2 n° 14
	IEC/EN/BS 60947-1
	IEC/EN/BS 60947-5-1
	UL508

Certificates

cULus

ETIM classification

ETIM 8.0

EC000029 -
Push-switch
button