



Triple-touch  
actuators, spring  
return - One  
middle extended  
buttons  
LPSB73

Product designation

Product type designation

**General characteristics**

Colour	Green/Red/Green
Type of positions	? - STOP - ?
Material	Aluminium and zinc alloy for metal parts and polyamide for plastic parts
IEC degree of protection	IP66, IP67 and IP69K

**Mechanical features**

Fixing	Without mounting adapter
Mounting adapter	LPXAU120M

**UL technical data**

UL degree of protection	Type1, 2, 3R, 4, 4X, 12, 12K
-------------------------	------------------------------

**Ambient conditions**

Temperature


Operating temperature

min	°C	-25
max	°C	+70

Storage temperature

min	°C	-40
max	°C	+85

**Dimensions**

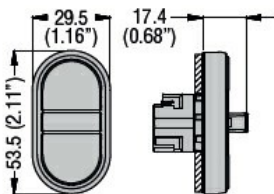

**Certifications and compliance**

Compliance

CSA C22.2 n° 14
IEC/EN/BS 60947-1
IEC/EN/BS 60947-5-1
UL508

Certificates

cULus

ETIM classification

ETIM 8.0

EC000029 -  
Push-switch  
button