



Illuminated  
mushroom head  
button actuators -  
Spring return Ø  
40mm/1.6"  
LPSBL61

## Product designation

## Product type designation

### General characteristics

|                          |                                                                          |
|--------------------------|--------------------------------------------------------------------------|
| Colour                   | Blue                                                                     |
| Material                 | Aluminium and zinc alloy for metal parts and polyamide for plastic parts |
| IEC degree of protection | IP66, IP67 and IP69K                                                     |

### Mechanical features

|                  |                          |
|------------------|--------------------------|
| Fixing           | Without mounting adapter |
| Mounting adapter | LPXAU120M                |


### UL technical data

|                         |                              |
|-------------------------|------------------------------|
| UL degree of protection | Type1, 2, 3R, 4, 4X, 12, 12K |
|-------------------------|------------------------------|

### Ambient conditions

|             |                       |     |    |     |
|-------------|-----------------------|-----|----|-----|
| Temperature | Operating temperature | min | °C | -25 |
|             |                       | max | °C | +70 |
|             | Storage temperature   | min | °C | -40 |
|             |                       | max | °C | +85 |

### Dimensions

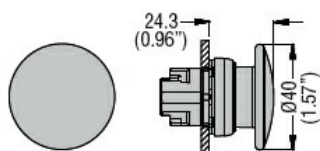

### Certifications and compliance

|              |                     |
|--------------|---------------------|
| Compliance   | CSA C22.2 n° 14     |
|              | IEC/EN/BS 60947-1   |
|              | IEC/EN/BS 60947-5-1 |
|              | UL508               |
| Certificates | cULus               |

### ETIM classification

ETIM 8.0

EC001038 -  
Front element for  
mushroom push-  
button