



Double-touch
actuators, spring
return white
indicator - Two
flush pushbuttons
LPSBL71

Product designation

Product type designation

General characteristics

Colour	Green/Red
Type of positions	Start / Stop
Material	Aluminium and zinc alloy for metal parts and polyamide for plastic parts
IEC degree of protection	IP66, IP67 and IP69K

Mechanical features

Fixing	Without mounting adapter
Mounting adapter	LPXAU120M

UL technical data

UL degree of protection	Type1, 2, 3R, 4, 4X, 12, 12K
-------------------------	------------------------------

Ambient conditions

Temperature


Operating temperature

min	°C	-25
max	°C	+70

Storage temperature

min	°C	-40
max	°C	+85

Dimensions

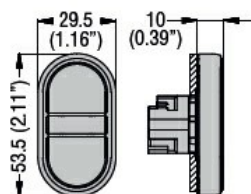

Certifications and compliance

Compliance

CSA C22.2 n° 14
IEC/EN/BS 60947-1
IEC/EN/BS 60947-5-1
UL508

Certificates

cULus

ETIM classification

ETIM 8.0

EC000029 -
Push-switch
button