




Product designation				Mechanical reset buttons, complete unit, spring return
Product type designation				LPSR10
General characteristics				
Colour				Blue
Material				Aluminium and zinc alloy for metal parts and polyamide for plastic parts
IEC degree of protection				IP66, IP67 and IP69K
Mechanical features				
Fixing				Without mounting adapter
Mounting adapter				LPXAU120M
UL technical data				
UL degree of protection				Type1, 2, 3R, 4, 4X, 12, 12K
Ambient conditions				
Temperature				
Operating temperature		min	°C	-25
		max	°C	+70
Storage temperature		min	°C	-40
		max	°C	+85

Dimensions

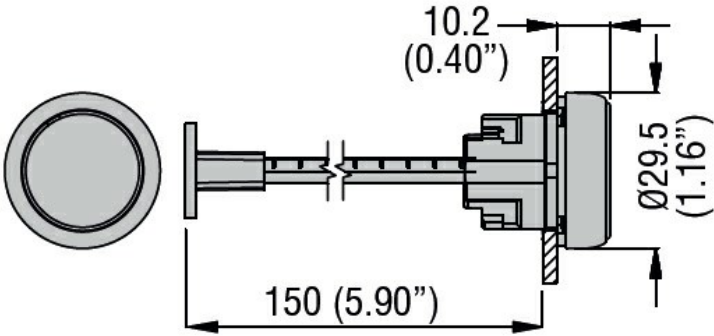

Certifications and compliance

Compliance	CSA C22.2 n° 14
	IEC/EN/BS 60947-1
	IEC/EN/BS 60947-5-1

UL508

Certificates

cULus

ETIM classification

ETIM 8.0

EC000029 -
Push-switch
button